



New product
for 2018



3 year
ext. warranty*

Inground Twin Direction

Architectural exterior LED lighting

- Durable die-cast aluminium construction
- IP67 protection against water ingress
- Stylish, contemporary design
- Matching colour temperature and finish to the Architectural Exterior range



^ JC17027



125mm

Classification

⚡ Class 1
IP67 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite

Construction

Body: Aluminium
Diffuser: Glass

JC17027

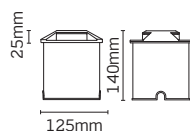

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens
JC17027	Inground Twin Direction	3000K	No	7W	150

*Requires online registration.