


Inground Spike Spotlight


Architectural exterior LED lighting

- Durable die-cast aluminium construction
- IP65 protection against water ingress
- Matching colour temperature and finish to the Architectural Exterior range
- Pre-wired with 900mm flex




NEW New product for 2018

 3 year ext. warranty*

 40° beam angle

Classification

 Class 1
IP65 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite

Construction

Body: Aluminium
Lens: Polycarbonate

JC17044

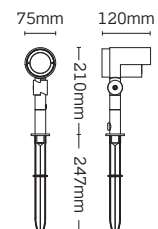

Code	Description	Col temp.	Watt	Lumens	LpcW
JC17044	Inground Spike Spotlight short	3000K	10W	750	75

*Requires online registration.

All data sheets and installation sheets available at jcc.co.uk