



New product
for 2018



3 year
ext. warranty*



40°
beam angle

Inground Spike Spotlight

Architectural exterior LED lighting

- Durable die-cast aluminium construction
- IP65 protection against water ingress
- Matching colour temperature and finish to the Architectural Exterior range
- Pre-wired with 900mm flex



Classification

⚡ Class 1
IP65 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite

Construction

Body: Aluminium
Lens: Polycarbonate

JC17045

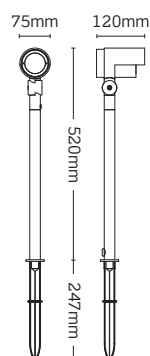

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Watt	Lumens	LpcW
JC17045	Inground Spike Spotlight tall	3000K	10W	750	75

*Requires online registration.