



New product  
for 2018



2 year  
product guarantee



Sensing  
options available

# LED Lantern Bottom Arm

## Contemporary LED wall lantern

- Decorative outdoor wall lantern
- IP44 protection against dust and moisture
- Integrated LED light source
- Durable die-cast aluminium construction



### Classification

⚡ Class 1

IP44 | 240V

### LED

4000K | CRI: Ra (80)

### Finishes


Black

### Construction

Body: Aluminium

Lens: Polycarbonate

JC39431 / JC39432

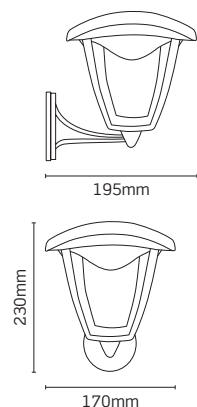

All data sheets and installation sheets  
available at [jcc.co.uk](http://jcc.co.uk)

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC39431	Bottom Arm LED Lantern	4000K	No	7.5W	290	41
JC39432	Bottom Arm LED Lantern with PIR	4000K	No	7.5W	290	41