



New product
for 2018



3 year
ext. warranty*



See p. 285
for matching bollard

Frosted Glazed Lantern

Architectural exterior LED lighting

- Durable die-cast aluminium construction
- Opal polycarbonate wall light
- IP54 protection against dust and moisture
- Matching colour temperature and finish to the Architectural Exterior range



Classification

⚡ Class 1
IP54 | 240V

LED

3000K | CRI: Ra (80)


Finishes

Anthracite

Construction

Body: Aluminium
Diffuser: Glass

JC17008

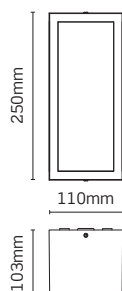

All data sheets and installation sheets
available at jcc.co.uk

Code	Description	Col temp.	Dim.	Watt	Lumens	LpcW
JC17008	Frosted Glazed Lantern	3000K	No	18W	662	36

*Requires online registration.