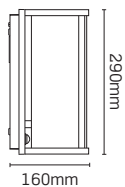
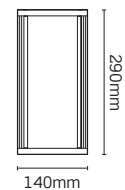


NEWNew product
for 20183 year
ext. warranty*Sensing
options availableSee p. 291
for matching bollard

✓ Rubber gasket lamp holder

Classification⊕ Class 1
IP54 | 240V**Lamp**E27 15W Max
Lamp not supplied**Finishes**Anthracite (**BLK**), White (**WH**)**Construction**Body: Aluminium
Diffuser: Glass

JC17036 / JC17037

All data sheets and installation sheets
available at jcc.co.uk

Glazed Lantern Mini

Architectural exterior LED lighting

- Stylish contemporary design
- Durable die-cast aluminium construction
- Toughened glass lantern with E27 lamp holder
- IP54 protection against dust and moisture
- PIR option available
- Matching colour temperature and finish to the Architectural Exterior range
- Suitable for use with LED lamps

✓ JC17036 (PIR)

**Code** **Description**

JC17036 Glazed Lantern Mini with PIR

JC17037 Glazed Lantern Mini

For Anthracite add **BLK** suffix, for White add **WH** suffix

*Requires online registration.