

Glazed Post Light

Architectural exterior LED lighting

- Stylish, contemporary design
- Durable die-cast aluminum construction
- Toughened glass post top with E27 lamp holder
- IP54 protection against dust and moisture
- Matching finish to the Architectural Exterior range
- Suitable for use with LED lamps



NEW

New product
for 2018



3 year
ext. warranty*



JC17038WH

Classification

Class 1
IP54 | 240V

Lamp

E27 15W Max
Lamp not supplied


Finishes

Anthracite (**BLK**), White (**WH**)

Construction

Body: Aluminium
Diffuser: Glass

JC17038

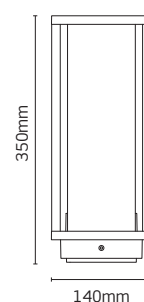

Code Description

JC17038 Glazed Post Light

For Anthracite add **BLK** suffix, for White add **WH** suffix

*Requires online registration.

All data sheets and installation sheets
available at jcc.co.uk