

APC Back-UPS® Pro 1000




Power-Saving, high performance power protection for office computers

The Back-UPS Pro provides abundant battery backup power, so you can work through medium and extended length power outages. It safeguards your equipment against damaging surges and spikes that travel along utility and data lines. And it features automatic voltage regulation (AVR), which instantly adjusts high and low voltages to safe levels, so you can work indefinitely during brownouts and overvoltages.

The Back-UPS Pro also includes unique “green” features, like power-saving outlets that automatically turn off idle peripherals. A high efficiency charging system and “AVR Bypass” also reduce power consumption. With the rest of the Back-UPS Pro’s standard features, this is the perfect unit to protect your productivity from the constant threat of bad power and lost data.

Product Features:

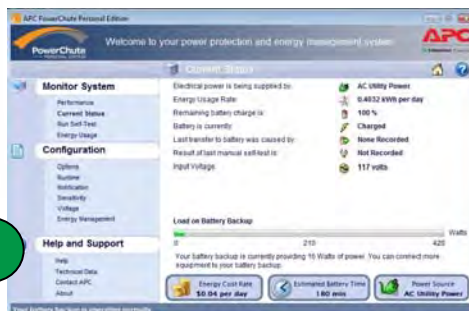

- 1 **LCD (Liquid Crystal Display)** gives the status of over 20 different utility and battery backup conditions.
- 2 **Automatic Voltage Regulation (AVR)** instantly corrects voltage fluctuations so you can work indefinitely through brownouts and overvoltages.
- 3 4 **“Battery Backup & Surge Protected” Outlets** keep a CPU, monitor and other critical devices running when the power goes out or fluctuates outside safe levels. (Includes one power-saving “Controlled” outlet).
- 4 4 **“Surge Only” Outlets** protect printers, faxes or other equipment without reducing battery capacity. (Includes two power-saving “Controlled” outlets).
- 5 **PowerChute Software** lets you use your computer to access additional power protection and management features:
 - Preserves your work, shuts down system during outages
 - Restarts your system, minimizing work disruptions
 - Enables customization of your Back-UPS settings
 - Monitors and displays power and battery status
- 6 **Data Line Surge Protection** guards against surges and spikes traveling over Ethernet or coax cable lines.
- 7 **Push Button Circuit Breaker** enables quick recovery from overloads.
- 8 **3 Yr Warranty**, \$150,000 Equipment Protection Policy and free technical support via phone or web.
- 9 **Automatic Diagnostic Testing** ensures your unit is ready when you need it.



Back-UPS Pro 1000 Specifications

Model Number	BR1000G
Output	
Output Capacity	1000 VA / 600 Watts
Output Voltage, Freq. (on utility)	120V, 50 or 60 Hz, +/- 3Hz (auto sensing)
Output Voltage, Freq. (on battery)	115V +/-8%, 50 or 60Hz +/-1Hz (auto sensing)
Output Connections	8 total NEMA 5-15R outlets: 4 battery & surge (including 1 <i>Master</i> & 1 <i>Controlled</i>) 4 surge protection only (including 2 <i>Controlled</i> outlets)
Waveform Type	Stepped Approximation to Sine Wave
Input	
Input Voltage, Frequency	120V, 50 or 60 Hz, +/- 3 Hz
Input Connection	6 ft cord with NEMA 5-15 plug
Surge Protection	
AC Power Surge Protection	All outlets
Data Line Surge Protection	Network: 10/100/1000 Base-T Ethernet (gigabit) Coax cable (CATV, SATV, modem, A/V)
Physical	
Unit Dimensions (H x W x D)	9.8 x 3.9 x 15.0" (25.0 x 10.0 x 38.2 cm)
Unit Weight	23.6 lbs (10.7 kg)
Shipping Dims. (H x W x D)	15.0 x 9.0 x 19.0" (38.1 x 22.9 x 48.3 cm)
Shipping Weight	28.0 lbs (12.7 kg)
Color	Black
UPC Code	731304278788
Battery	
Battery Type	Sealed, lead-acid, maintenance-free
Extended run battery pack compatibility	No
Management	
Alarms	Visual (LCD) and audible alarms
Auto-Shutdown Software	PowerChute Personal Edition (via USB and serial interface)
Safety	
Certification/Approvals	FCC Part 15 Class B, TUV, UL1778

APC by Schneider Electric

132 Fairgrounds Rd
West Kingston, RI 02892
Tel: 800-800-4272
www.apc.com

