



**Color:** White

**UPC Code:** 078477240618

**Country Of Origin:** United States

## 1221-SW

20 Amp, 120/277 Volt, Toggle Single-Pole AC Quiet Switch, Heavy Duty Spec Grade, Grounding, Back & Side Wired - WHITE

Leviton's Industrial Grade AC toggle switches for extra heavy-duty applications represent top-of-the-line quality and peak performance. Leviton uses the finest materials available and the highest production standards to produce industrial switches of unmatched versatility and reliability.

### Technical Information

#### AC Horsepower Ratings

**HP Rating:** 1HP-120V 2HP-240V-277V

#### Electrical Specifications

**Amperage:** 20 A

**Dielectric Voltage:** Withstands 1500V for 1 minute

**Temperature Rise:** Maximum 30 degrees C rise

**Voltage:** 120/277 VAC

**Grounding:** Self-Grounding

#### Environmental Specifications

**Flammability:** Rated V-2 per UL 94

**Operating Temperature:** -40°C to 65°C

#### Material Specifications

**Actuator Material:** Thermoplastic

**Base Material:** PBT

**Body Material:** Thermoplastic

**Color:** White

**Contacts:** Silver-Cadmium .031 Thick

**Cover Material:** Nylon

**Strap Material:** Steel

**Terminal Screws:** Steel 8-32

**Toggle:** Polycarbonate

#### Mechanical Specifications

**Product ID:** Stamped on Strap

**Terminal Accom.:** 14-#10 AWG back wired; #14-#12 AWG side wired

**Terminal ID:** Brass-Hot, Green-Ground, Silver-Neutral

**Termination:** Back or Side Wire

**Torque Range:** 12-14 inch pounds

#### Product Features

**Actuator Material:** Thermoplastic

**Color:** White

**Voltage:** 120/277 VAC

**Warranty:** 2-Year Limited

**Grade:** Heavy-Duty Industrial Specification Grade

**Function:** Single-Pole

**Device Type:** Toggle Switch

#### Standards and Certifications

**ANSI:** C-73

**CSA C22.2 No. 111:** File #152105

**NEMA:** WD-1 & WD-6

**NOM:** 057


**UL Fed Spec WS896F:** File #E7458

**UL Standard:** UL 20

**Warranty:** 2-Year Limited



**SINGLE-POLE**  
**Wiring Diagram**  
**Single Pole**

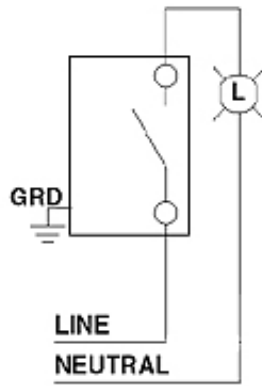

**SPECIFICATION SUBMITTAL**

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

**Leviton Manufacturing Co., Inc.**

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):

+1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-

1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:

[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

