



Color:  Ivory

UPC Code: 078477239896

Country Of Origin: United States

## 1221-2I

20 Amp, 120/277 Volt, Toggle Single-Pole AC Quiet Switch, Extra Heavy Duty Spec Grade, Self Grounding, Back & Side Wired, UL Fed Spec WS896E: File #E7458: No technical changes to product/compliant with WS 896/F - IVORY

Leviton's Industrial Grade AC toggle switches for extra heavy-duty applications represent top-of-the-line quality and peak performance. Leviton uses the finest materials available and the highest production standards to produce industrial switches of unmatched versatility and reliability.

### Technical Information

AC Horsepower Ratings

**HP Rating:** 1HP-120V 2HP-240V

Electrical Specifications

**Amperage:** 20 A

**Dielectric Voltage:** Withstands 1500V for 1 minute

**Endurance:** 50,000 cycles minimum

**Grounding:** Self-Grounding

**Overload UL20 Test:** 100 cycles of OL at 4.8 times rated current

**Temperature Rise:** Maximum 30 degrees C rise

**Voltage:** 120/277 VAC

Environmental Specifications

**Flammability:** Rated V-2 per UL 94

**Operating Temperature:** -40°C to 65°C

Material Specifications

**Base Material:** Thermoplastic

**Color:** Ivory

**Contact Material:** Silver Alloy

**Cover Material:** Thermoplastic

**Ground Clips:** Brass

**Grounding Screw:** Brass 8-32

**Strap Material:** .048" Thick Galvanized Steel

**Terminal Screws:** Brass 8-32

**Toggle:** Polycarbonate

Mechanical Specifications

**Product ID:** Ratings are permanently marked on device

**Terminal Accom.:** 14-#10 AWG back wired; #14-#12 AWG side wired

**Terminal ID:** Brass-Hot Black-Hot White-Neutral Green-Gnd

**Torque Range:** 12-14 inch pounds

**Termination:** Back or Side Wire

Product Features

**Color:** Ivory

**Grade:** Extra Heavy-Duty Industrial Specification Grade

**Function:** Single-Pole

**Device Type:** Toggle Switch

Standards and Certifications

**ANSI:** C-73

**CSA C22.2 No. 111:** File #152105

**NEMA:** WD-1 & WD-6

**NOM:** 057

**RoHS:** Compliant


**UL Fed Spec WS896E:** File #E7458

**UL Standard:** UL 20

**Warranty:** 10 Year Limited



**SINGLE-POLE**  
**Wiring Diagram**  
**Single Pole**

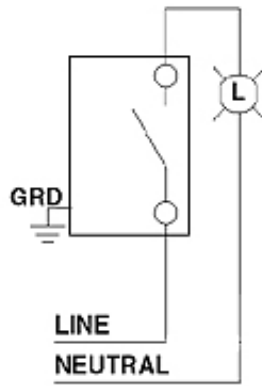

**SPECIFICATION SUBMITTAL**

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

**Leviton Manufacturing Co., Inc.**  
 201 North Service Road, Melville, NY 11747  
 Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):  
 +1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**  
 165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·  
 FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**  
 Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-  
 1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)  
 © 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**  
 If you would like to know where your local Leviton office is located please go to:  
[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

