



Color:  Ivory

UPC Code: 078477239896

Country Of Origin: United States

1221-2I

20 Amp, 120/277 Volt, Toggle Single-Pole AC Quiet Switch, Extra Heavy Duty Spec Grade, Self Grounding, Back & Side Wired, UL Fed Spec WS896E: File #E7458: No technical changes to product/compliant with WS 896/F - IVORY

Leviton's Industrial Grade AC toggle switches for extra heavy-duty applications represent top-of-the-line quality and peak performance. Leviton uses the finest materials available and the highest production standards to produce industrial switches of unmatched versatility and reliability.

Technical Information

AC Horsepower Ratings

HP Rating: 1HP-120V 2HP-240V

Electrical Specifications

Amperage: 20 A

Dielectric Voltage: Withstands 1500V for 1 minute

Endurance: 50,000 cycles minimum

Grounding: Self-Grounding

Overload UL20 Test: 100 cycles of OL at 4.8 times rated current

Temperature Rise: Maximum 30 degrees C rise

Voltage: 120/277 VAC

Environmental Specifications

Flammability: Rated V-2 per UL 94

Operating Temperature: -40°C to 65°C

Material Specifications

Base Material: Thermoplastic

Color: Ivory

Contact Material: Silver Alloy

Cover Material: Thermoplastic

Ground Clips: Brass

Grounding Screw: Brass 8-32

Strap Material: .048" Thick Galvanized Steel

Terminal Screws: Brass 8-32

Toggle: Polycarbonate

Mechanical Specifications

Product ID: Ratings are permanently marked on device

Terminal Accom.: 14-#10 AWG back wired; #14-#12 AWG side wired

Terminal ID: Brass-Hot Black-Hot White-Neutral Green-Gnd

Torque Range: 12-14 inch pounds

Termination: Back or Side Wire

Product Features

Color: Ivory

Grade: Extra Heavy-Duty Industrial Specification Grade

Function: Single-Pole

Device Type: Toggle Switch

Standards and Certifications

ANSI: C-73

CSA C22.2 No. 111: File #152105

NEMA: WD-1 & WD-6


NOM: 057

RoHS: Compliant

UL Fed Spec WS896E: File #E7458


UL Standard: UL 20

Warranty: 10 Year Limited

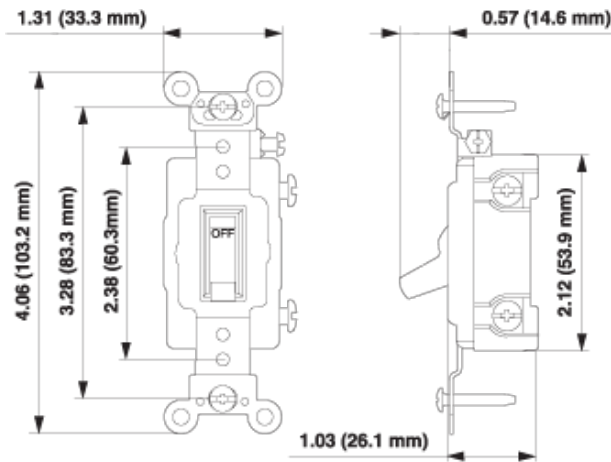

SINGLE-POLE

Wiring Diagram Single Pole

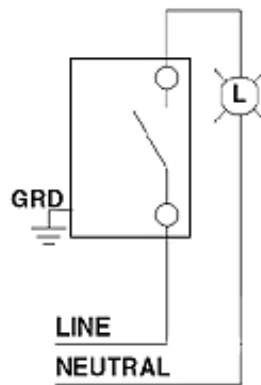

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
JOB NUMBER:		

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/

