



Color:  Orange

UPC Code: 078477052457

Country Of Origin: Mexico

NEMA:
5-20R



5362-IG

Isolated Ground Duplex Receptacle Outlet, Heavy-Duty Industrial Specification Grade, Smooth Face, 20 Amp, 125 Volt, Back and Side Wire, NEMA 5-20R, 2-Pole, 3-Wire, Self-Grounding - Orange

Leviton's line of Extra Heavy-Duty Industrial Grade receptacles are designed and manufactured to withstand the harsh conditions typically associated with industrial environments. Available in a wide variety of configurations, including isolated ground, tamper-resistant, hospital grade, etc., these Industrial Grade devices are the electrical contractor's choice for use in factories, schools, hospitals and commercial office buildings.

Technical Information

AC Horsepower Ratings

At Rated Voltage: 1 HP

Electrical Specifications

Amperage: 20 A

Dielectric Voltage: Withstands 3000 V min

Grounding: Self-Grounding

Pole: 2

Temperature Rise: Max 30C
temperature rise at full rated current

Voltage: 125 VAC

Wire: 3

Environmental Specifications

Flammability: Rated V-0 per UL 94

Operating Temperature: -40°C to 75°C

Material Specifications

Body Material: PBT Polyester Blend

Color: Orange

Face Material: PBT Polyester Blend

Grounding Screw: #8 Hex Head, Triple-Drive Brass

Line Contacts: 0.030" Phosphor Bronze

Strap Material: Steel (Galvanized G60)

Terminal Screws: #8 Triple-Drive Brass

Mechanical Specifications

Product ID: Ratings are permanently part of devices

Terminal Accom.: #14-#10 AWG

Terminal ID: Brass-Hot, Silver-Neutral, Green-Ground

Termination: Back and Side Wire

Product Features

Body Material: PBT Polyester Blend

Color: Orange

Device Type: Duplex Receptacle Outlet

Face Material: PBT Polyester Blend

Feature 4: Smooth Face

Function: Isolated Ground

Grade: Heavy-Duty Industrial Specification Grade

NEMA: 5-20R

Termination: Back and Side Wire

Standards and Certifications

ANSI: C-73

CSA C22.2 No. 42: File 152105


NEMA: WD-1 & WD-6

NOM: 057

UL498: File E13399

UL Fed Spec WC-596: File E13399

Warranty: 10 Years

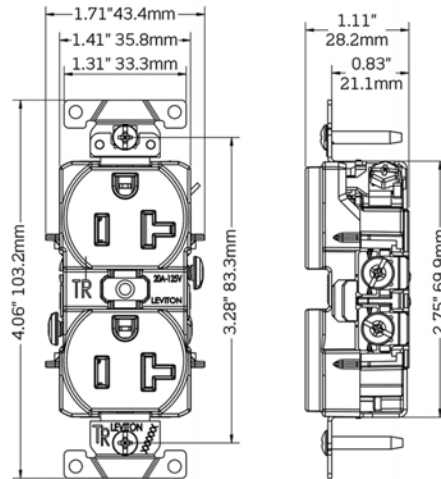

Drawing Applies to 15 & 20A Devices

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):
+1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·
FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-
1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:
www.leviton.com/international/contacts/

