

DS-1100KI Network Keyboard




Key Features

- 7" TFT Touch Screen at 800 × 480 Resolution
- 4-Axis Joystick
- Live View and Video Playback on Screen at 1080p
- Compatible with DVR/DVS, Matrix, Network Camera/Dome, PC-DVR, etc.
- Macro Command Operation and Shortcut Keys
- Display Decoded Video on Monitor or Video Wall
- 1-Channel Video Decoding for Local Live View
- Video Capture and Recording to Local U-Flash Disk
- Supports 3 Operators, Each Operating 1280 Devices
- Configure Using Web Server or Keyboard Configuration Tool
- Configure and Control MVC System
- Control Analog Matrix with ZT-1.0, ZT-2.0, EXTRON, or CREATOR Protocol
- Control up to 255 Analog Domes via RS-485


DS-1100KI	
Interface	
Control Mode	IP-based
TFT LCD Panel	7" TFT LCD monitor with touch panel Resolution: 800 × 480
Joystick	4-axis joystick
Audio Input/Output	
Line In	1-ch, 3.5 mm connector (2.0 Vp-p, 1 k Ω)
Audio Out	1-ch, 3.5 mm connector (linear, 560 Ω)
External Interface	
Network Interface	1 10M/100M/1000M Ethernet interface
RS-232 Interface	1 RS-232 interface
RS-485 Interface	1 RS-485 interface
USB Interface	1 USB 2.0 (for data storage and device upgrade)
General	
Power Supply	12 VDC
Power Consumption	≤ 15 W
Working Temperature	-10° C to 55° C (14° F to 131° F)
Working Humidity	10% to 90%
Dimensions (W × D × H)	435 mm × 193 mm × 110 mm (17.13" × 7.60" × 4.33")
Weight	2 kg (4.41 lb)

Landmarks

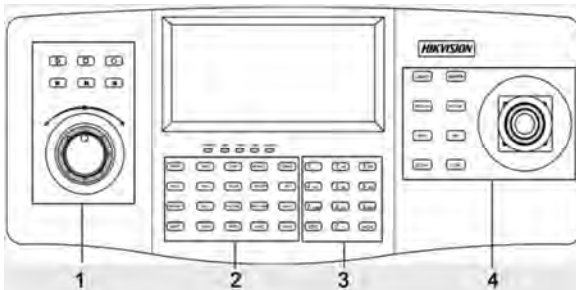

Top Panel

- | | |
|--------------------|-----------------------|
| 1. Record Playback | 2. Functional Buttons |
| 3. Numeric Buttons | 4. PTZ Control Area |

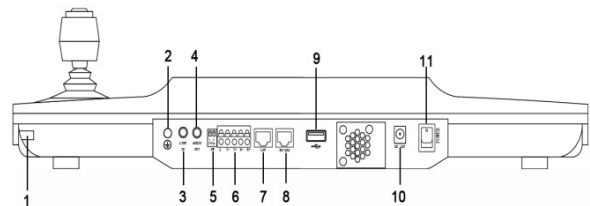

Rear Panel

- | | |
|------------------|-------------------------|
| 1. Touch Pen | 2. GND |
| 3. Line In | 4. Audio Out |
| 5. Reserved | 6. RS-485 Interface |
| 7. LAN | 8. RS-232 Interface |
| 9. USB Interface | 10. 12V DC Power Supply |
| 11. Power On/Off | |

Order Model

DS-1100KI