

DS-D5019QE-B 19" LCD Display Monitor



Hikvision's DS-D5019QE-B 19-inch LCD monitor provides excellent color rendition and enhanced, 1366 x 768 resolution. It features an LED direct-lit backlight with uniform brightness and no boundary shadow.

The DS-D5019QE-B is constructed of high-quality components and materials for 24/7 use.


Available Models:
DS-D5019QE-B

- 1366 x 768 Resolution
- LED Backlit Technology
- Wide Angle View: 90° (H)/65° (V)
- 3D Comb Filter
- 3D De-Interlace
- 3D Noise Reduction
- Input: HDMI, VGA
- Highly Reliable 24h/Day Functioning

Specifications

DS-D5019QE-B	
Display Type	LED Backlit TFT LCD
Screen Size	18.5"
Pixel Pitch (H x V)	0.30 mm x 0.30 mm
Maximum Resolution	1366 x 768
Brightness	200 cd/m ² (typical)
Contrast	600:1
Response Time	5 ms
Color	16.7 M
Viewing Angle	Horizontal 90°, vertical 65°
Input	
VGA	VGA x 1
HDMI	HDMI x 1
Mounting	
VESA	75 mm x 75 mm
General	
Power Supply	100 to 240 VAC, 50/60 Hz
Consumption	< 25 W (on), < 0.5 W (standby)
Operating Temperature	32° F to 104° F (0° C to 40° C)
Operating Humidity	10% to 85% (no condensation)
Storage Temperature	-4° F to 131° F (-20° C to 55° C)
Storage Humidity	5% to 95% (no condensation)
Dimensions (W x H x D)	17.54" x 10.83" x 1.76" (445.58 mm x 274.99 mm x 44.6 mm)
Weight	Gross weight: 7.72 lbs (3.5 kg), net weight: 6.17 lbs (2.8 kg)
Included Accessories	VGA(D-Sub) cable x 1, power cord x 1, base bracket x 1, user manual x 1, warranty card x 1

Interface

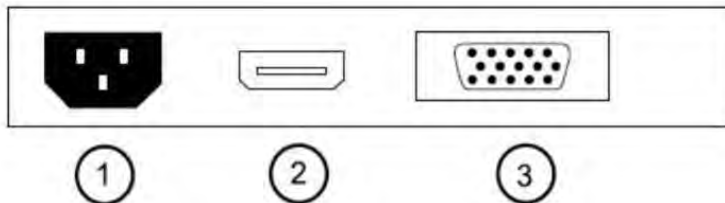

Number	Description
1	Power Input
2	HDMI Digital Signal Output
3	VGA Analog Signal Input