


DS-2CD2232-I5

3 MP EXIR Bullet Network Camera


EXIR

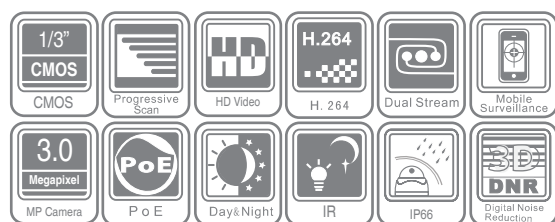

Key Features

- Full HD1080p Real-Time Video
- 3.0 Megapixel (2048 x 1536) Resolution
- DWDR, 3D DNR, and BLC
- EXIR Illuminators: Up to 50 Meters
- IP66
- PoE

Dimensions

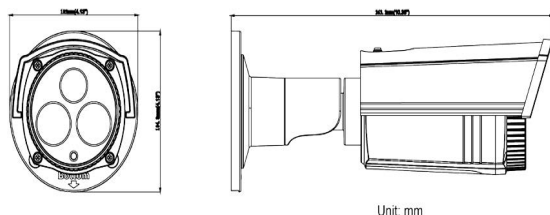

Accessories



Order Models

DS-2CD2232-I5

DS-2CD2232-I5	
Camera	
Image Sensor	1/3" progressive scan CMOS
Minimum Illumination	0.19 lux @ f/2.0, AGC on 0 lux with IR
Shutter Speed	1/25 s (1/30 s) to 1/100,000 s
Lens	4 mm @ f/2.0 (6 mm, 12 mm options) angle of view: 75.8°
Lens Mount	M12
Day/Night	ICR
Digital Noise Reduction	3D DNR
Wide Dynamic Range	Digital WDR
Backlight Compensation	Yes, zone configurable
Compression Standard	
Video Compression	H.264/MJPEG
H.264 Compression Profile	Main Profile
Bit Rate	32 Kbps to 16 Mbps
Dual Stream	Yes
Image	
Maximum Image Resolution	2048 x 1536
Frame Rate	60 Hz: 15 fps (2048 x 1536), 30 fps (1920 x 1080), 30 fps (1280 x 720)
Image Settings	Saturation, brightness, contrast adjustable through client software or Web browser
Network	
Network Storage	NAS
Alarm Triggers	Motion detection, tampering alarm
Protocols	TCP/IP, HTTP, DHCP, DNS, DDNS, RTP, RTSP, PPPoE, SMTP, NTP, SNMP, HTTPS, FTP, 802.1X, QoS
System Compatibility	ONVIF, PSIA, CGI, ISAPI
General Functionalities	User authentication, watermark
Interface	
Communication Interface	1 RJ-45 10M/100M Ethernet port
General	
Operating Conditions	-30° C to 60° C (-22° F to 140° F), humidity 95% or less (non-condensing)
Power	12 VDC ±10%, PoE (802.3af)
Power Consumption	Maximum 7 W (9 W with ICR on)
Ingress Protection	IP66
EXIR Range	Up to 50 meters
Dimensions	100.5 mm x 88.1 mm x 157.3 mm (3.96" x 3.47" x 6.19")
Weight	700 g (1.5 lbs)