


<b>Product Description:</b>	2 RU Horizontal mount PDU
<b>Socket Type:</b>	AS / NZS3112 10A sockets
<b>Number of Sockets:</b>	10
<b>Power Input:</b>	Single input at the left end of the PDU
<b>Mounting Type Brackets:</b>	Inverse installation type
<b>Cable Plug:</b>	AS / NZS3112 10A plug
<b>Control Function:</b>	Overload protection & LED power indicator
<b>Case:</b>	2RU in black Aluminium
<b>Cable Specifications:</b>	3 meters 3x1.5sqmm
<b>Product Size:</b>	482.6mm
<b>Mounting Length:</b>	465mm
<b>Case Length:</b>	432.6mm
<b>Fittings Supplied:</b>	Cage screws and nuts
<b>Size of Internal Wiring:</b>	3sqmm bus bars (0.5mm x 6mm flat copper bar)
<b>Rated Voltage:</b>	240VAC
<b>Rated Current:</b>	10A
<b>Maximum Power:</b>	2400 watts
<b>RoHS:</b>	Yes

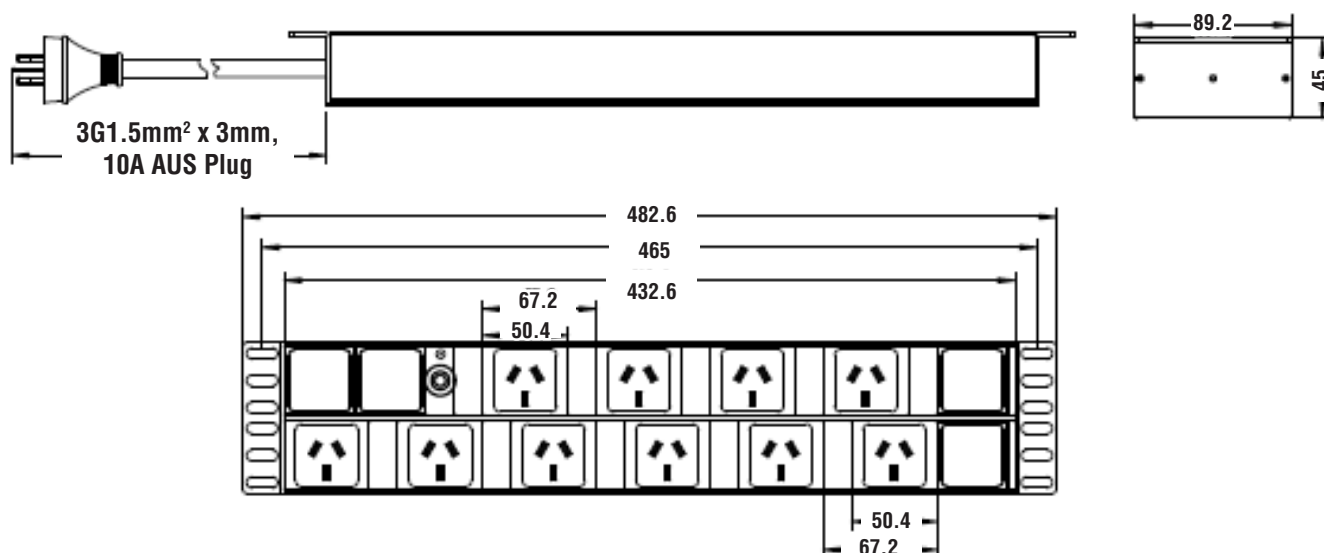

Measurements are in millimetres.