




AD1002 Two Channel Digital Power Amplifier

Features:

- MAIN / INTERRUPT priority input switching*
- MAIN auxiliary output*
- Speaker A/B switching*
- Front panel Balance and Volume controls*
- Signal sensing "Power On" and Trigger mode*
- Rear mounted treble and bass controls*
- Rack mountable (rack ears included)*

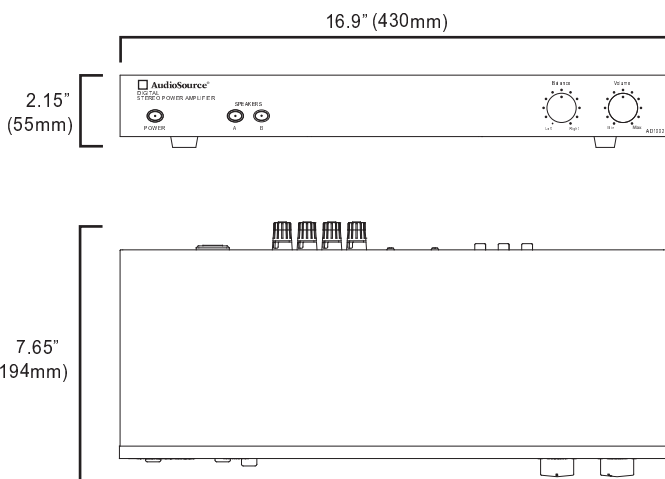

Specifications:

Stereo (8 ohm):	50W per channel, <.2% THD+N
Stereo (4 ohm):	75W per channel, <.2% THD+N
Bridged Mono (8 ohm):	160W, 1kHz, <.2% THD+N
Frequency Response:	20Hz ~ 20kHz
Signal to Noise Ratio:	100dB below 50W output into 8 ohms w/20kHz Lowpass filter
Channel Separation:	60dB
Input Sensitivity:	700mV input for rated 50W output into 8 ohms
Bass/Treble Control:	+/- 12dB @ 100Hz and 10kHz
AC Power Consumption:	200W maximum
Net Weight:	4.7lbs / 2.2kgs
Gross Weight:	5.6lbs / 2.5kgs

AD1002
AudioSource 2 x 50 Watt Digital Amplifier

MSRP : \$229.99 MAP : \$179.99 UPC: 041087906564 MP: 4
Shipping Carton Weight / Dimensions lbs-in: 25.2lbs - 21" x 16.2" x 10" kg-mm: 11.4 - 533 x 411 x 254



www.audiosource.net
13970 SW 72nd Ave Portland
OR 97223 Tel: 503.914.4688