


## AD5012 Digital Multi-Zone Power Amplifier

### Features:

12 Channels (6 stereo zones)  
12 Rear mounted level controls  
12 Independent Inputs, 2 Buss Inputs  
Buss Master Level Controls  
Phoenix-style speaker connectors  
LED Status indicator lights

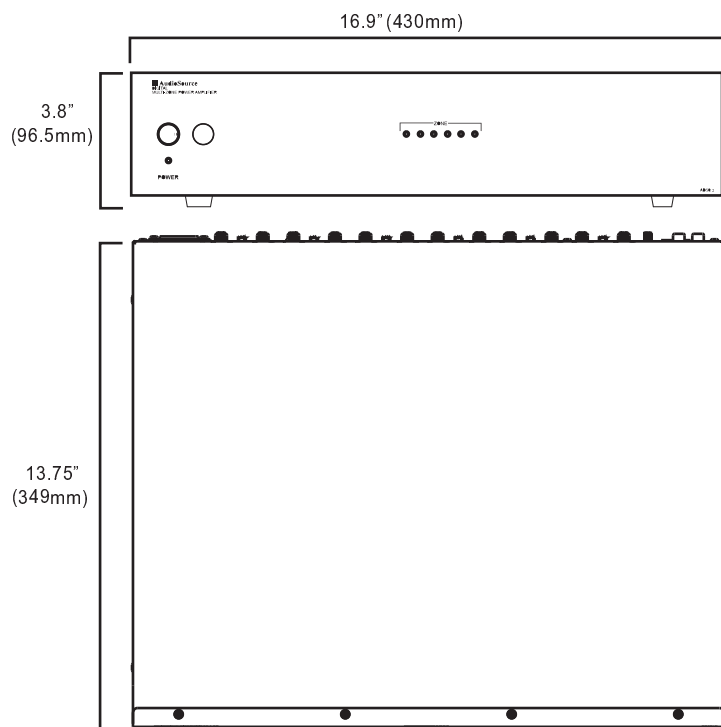

### Features (continued)

Digital Optical line input  
Multi-function IR remote control  
Signal sensing "Power On" and Trigger mode  
Rear mounted treble and bass controls  
Rack mountable (rack ears included)

### Specifications:

Stereo (8 ohm):	12 x 50W per channel, <.2% THD+N
Stereo (4 ohm):	12 x 75W per channel, <.2% THD+N
Bridged Mono (8 ohm):	6 x 125W, 1kHz, <.2% THD+N
Frequency Response:	20Hz ~ 20kHz
Signal to Noise Ratio:	100dB below 50W output into 8 ohms w/20kHz Lowpass filter/A-Wgt
Channel Separation:	80dB
Input Sensitivity:	Variable, 350mV to 2.8V for rated power into 8 ohms
Bass/Treble Control:	+/- 12dB @ 100Hz and 10kHz
AC Power Consumption:	1000W maximum
Net Weight:	17lbs / 7.7kgs
Gross Weight:	20lbs / 9.0kgs

AD5012  
AudioSource 12 x 50 Watt Digital Multi-Zone Amplifier

MSRP : \$1299.99      MAP : \$999.99      UPC: 041087906601      MP: 1  
Shipping Carton Weight / Dimensions lbs-in: 19lbs - 22" x 19" x 9"      kg-mm: 8.6 - 559 x 483 x 229



www.audiosource.net  
13970 SW 72nd Ave Portland  
OR 97223 Tel: 503.914.4688