




AMP100VS Stereo Power Amplifier

Features:

MAIN / INTERRUPT priority input switching
MAIN auxiliary output
Speaker A/B switching
Front panel Balance and Volume controls
Signal sensing "Power On" and Trigger mode
Rear mounted treble and bass controls

Specifications:

Stereo (8 ohm): 50W per channel, <0.2% THD+N
Stereo (4 ohm): 60W per channel, <0.2% THD+N
Bridged Mono (8 ohm): 150W, 1kHz, <1% THD+N
Frequency Response: 10Hz ~ 30kHz, +0dB/ -2dB
Signal to Noise Ratio: 100dB below 50W output into 8 ohms
Channel Separation: 70dB @ 1kHz, referred to 50W output into 8 ohms
Input Sensitivity: 700mV input for rated 50W output into 8 ohms
Bass/Treble Control: +/- 12dB @ 100Hz and 10kHz
AC Power Consumption: 500W maximum
Product Weight: 10.1lbs / 4.6kgs
Single Unit Packaged Weight: 11.25lbs / 5.1kgs

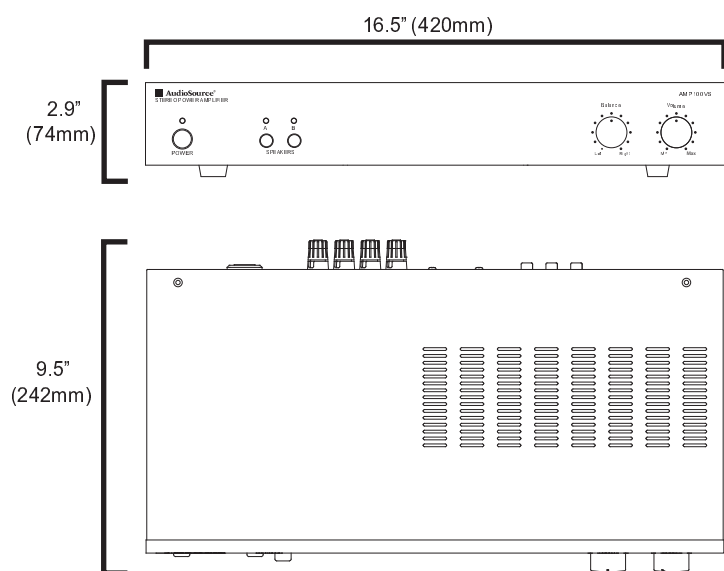

AMP100VS
AudioSource 2 x 50 Watt Stereo Amplifier

MSRP : \$179.99

MAP : \$139.99

UPC: 041087906687

MP: 4

Shipping Carton Weight / Dimensions lbs-in: 47lbs - 21.5" x 20" x 12" kg-mm: 21.3 - 546 x 508 x 304



www.audiosource.net
13970 SW 72nd Ave Portland
OR 97223 Tel: 503.914.4688