



## AMP210VS Stereo Power Amplifier

### Features:


MAIN / INTERRUPT priority input switching  
MAIN auxiliary output  
Speaker A/B switching  
Signal sensing "Power On" and Trigger mode  
Rear mounted treble and bass controls  
High level input

### Features (Continued)

Front panel balance and volume trim controls  
Independent rear left / right master level controls  
Front panel diagnostic LEDs  
Triple-Darlington Power Amplifier Stages  
Dual-differential error amplifiers  
Rack Mountable (Rack Mount Included)  
Front Panel Clip/Diagnostic LEDs

### Specifications:

Stereo (8 ohm):	100W per channel, <0.2% THD+N
Stereo (4 ohm):	125W per channel, <0.2% THD+N
Bridged Mono (8 ohm):	250W, 1kHz, <0.2% THD+N
Frequency Response:	10Hz ~ 50kHz, +0dB/ -3dB
Signal to Noise Ratio:	100dB below 100W output into 8 ohms
Channel Separation:	70dB @ 1kHz, referred to 100W output into 8 ohms
Input Sensitivity:	Variable, 350mV to 2.8V for rated power into 8 ohms
Bass/Treble Control:	+/- 12dB @ 100Hz and 10kHz
AC Power Consumption:	700W maximum
Net Weight:	24lbs / 10.9kgs
Gross Weight:	30lbs / 13.6kgs

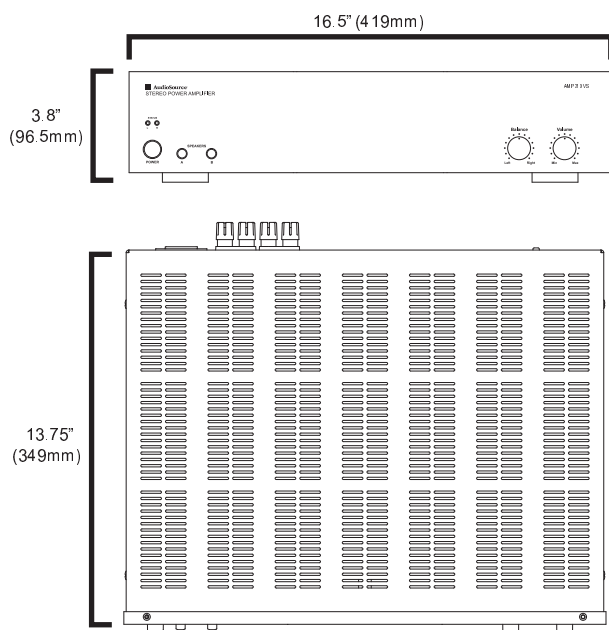

AMP210VS  
AudioSource 2 x 100 Watt Stereo Amplifier

MSRP : \$699.99

MAP : \$529.99

UPC: 041087906700

MP: 1

Shipping Carton Weight / Dimensions lbs-in: 30lbs - 21.2" x 18" x 8" kg-mm: 13.6 - 538 x 457 x 203



www.audiosource.net  
13970 SW 72nd Ave Portland  
OR 97223 Tel: 503.914.4688