


# BC200-CD Conduit to Beam Clamp – BC200CD1B



- Eliminates offset bending conduit
- Threaded hole on back
- Ideal for electrical, mechanical, and HVAC applications

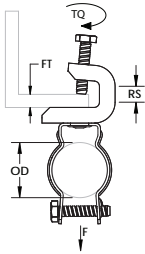

Part Number	BC200CD1B
Material	Steel
Finish	Electrogalvanized
Outer Diameter (OD)	0.74" – 1.05"
EMT Conduit Size	3/4"
Rigid Conduit Size	3/4"
Flange Thickness (FT)	1/2" Max
Rod Size (RS)	1/4"
Torque (TQ)	3 ft lb
Static Load (F)	100 lb
Certifications	cULus
Standard Packaging Quantity	50 pc
UPC	78285619310
EAN-13	8711893005684

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2019 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

