



nVent CADDY Cablecat J-Hook with Hammer-On Flange Clip, Swivel – CAT12912

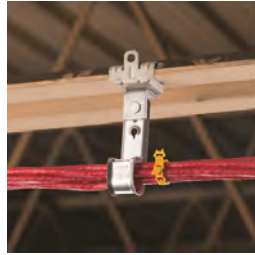

- Hammer-on beam clamp with attached nVent CADDY Cablecat J-Hook
- Supports low voltage cables
- Rotates 360 degrees to support various directional runs of cable

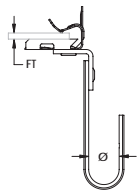

Part Number	CAT12912
Material	Steel Spring Steel
Finish	Pregalvanized nVent CADDY Armour
Diameter (Ø)	3/4"
Flange Thickness (FT)	9/16" – 3/4"
Certifications	cULus
Standard Packaging Quantity	20 pc
UPC	78285633319
EAN-13	8711893816730

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2019 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

