



nVent CADDY Cablecat J-Hook with BC200 Beam Clamp, Swivel – CAT12BC200B

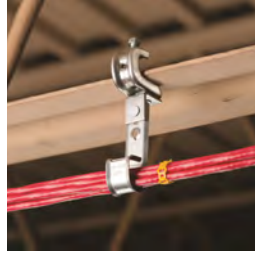

- Beam clamp with attached nVent CADDY Cablecat J-Hook
- Supports low voltage cables
- Rotates 360 degrees to support various directional runs of cable

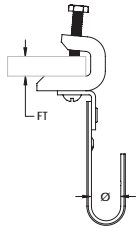

Part Number	CAT12BC200B
Material	Steel
Finish	Pregalvanized
Diameter (Ø)	3/4"
Flange Thickness (FT)	1/8" – 1/2"
Certifications	cULus
Standard Packaging Quantity	40 pc
UPC	78285633315
EAN-13	8711893814330

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2019 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

