


nVent CADDY Cat HP J-Hook Clip to BC200 Beam Clamp, Swivel – CATHPBC200B



- Easy installation to beam flanges
- Rotates 360 degrees to support various directional runs of cable
- Requires no screws, rivets or special tools for assembly
- J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability
- Link to J-Hooks in one of multiple color options to aid in pathway identification and organization
- Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations
- nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

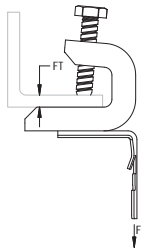

Part Number	CATHPBC200B
Material	Steel Spring Steel
Finish	Electrogalvanized nVent CADDY Armour
Flange Thickness (FT)	1/8" – 5/8"
Static Load (F)	100 lb
Certifications	cULus DIN 4102-12 abP P-3117/339/14-MPA BS (Germany) E30 E60 E90
Standard Packaging Quantity	25 pc
UPC	78285661773
EAN-13	8711893048940

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2019 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

