


# nVent CADDY Cat HP J-Hook Clip to C Purlin Clip – CATHPVF14



- Hammer-on or install from the floor with the VAFT tool
- Requires no screws, rivets or special tools for assembly
- J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability
- Link to J-Hooks in one of multiple color options to aid in pathway identification and organization
- Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations
- nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

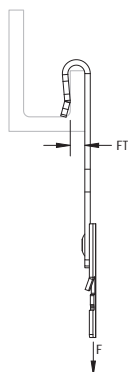

|                             |                    |
|-----------------------------|--------------------|
| Part Number                 | CATHPVF14          |
| Material                    | Spring Steel       |
| Finish                      | nVent CADDY Armour |
| Flange Thickness (FT)       | 1/16" – 1/4"       |
| Static Load (F)             | 160 lb             |
| Certifications              | cULus              |
| Standard Packaging Quantity | 50 pc              |
| UPC                         | 78285661780        |
| EAN-13                      | 8711893049015      |

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2019 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

