

■DESCRIPTION


The L-11S is a line input module to be used in conjunction with the 900 series components and other TOA's equipment. It has a transformer balanced line matching input with terminal block connector, and mute-receive function.

■SPECIFICATIONS

\* 0 dB=1 V

Input Sensitivity	-18 dB* (Rated output: -20 dB*)
Current Consumption	5 mA
Input Impedance	600 Ω, balanced transformer-isolated
Frequency Response	20 Hz - 20 kHz ±1.5 dB
Signal Muting Level	60 dB (at 1 kHz)
Connector	Removable terminal block (3P)
Dimensions	35 (W) × 78 (H) × 88 (D) mm (1.38" × 3.07" × 3.46")
Weight	Max. 80 g (0.18 lb)

■APPEARANCE

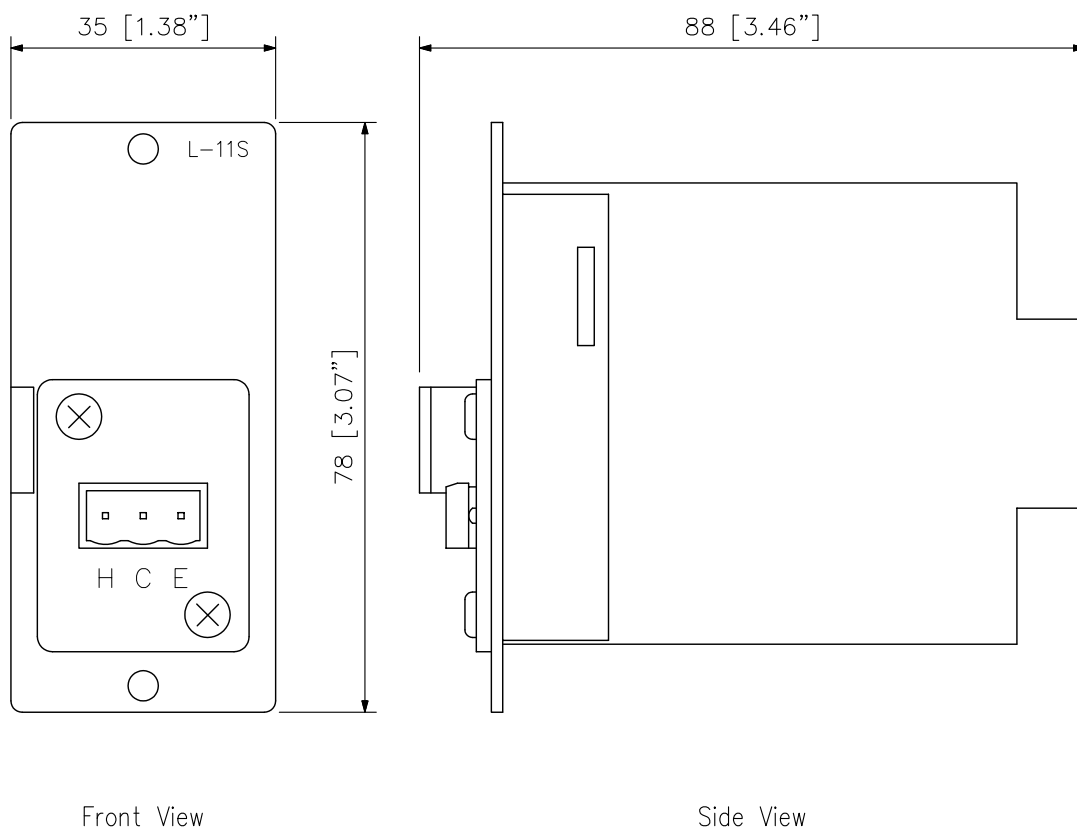

UNIT:mm SCALE:1/1