



Energizer® Vision HD Headlamp

HDBIN32EB


The *Energizer*® Vision HD headlamp is another innovative headlamp solution from the *Energizer* headlamp line. Featuring LED technology, users get an extremely bright, lightweight hands-free solution with ample run time capability. Patented optics offer exceptional direct and peripheral vision, making the *Energizer* Vision HD a perfect light for home, work and outdoor activities. Thanks to *Energizer*® Smart Dimming technology, users can control the intensity of light from 100% to 10%, and enjoy Next Push Off technology to avoid unnecessary switch cycles. With an adjustable head strap, water-resistant design and pivoting head to direct light exactly as needed, this headlight is another way *Energizer* continues to deliver innovative lighting solutions.



Provides
200 Lumens
of Light



Provides
Run Time
of 8hrs
and 30
mins

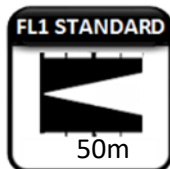

Shines Light
on Objects
50 Meters
Away



Sustains 1
Meter
Drop Test



Works
even after
splashing
water on
all sides

DESIGN BENEFITS

- ✓ *Energizer*® Smart Dimming technology to control light intensity
- ✓ Next Push Off to avoid unnecessary switch cycles
- ✓ Water-resistant design
- ✓ Shatterproof lenses
- ✓ Pivoting head to direct light where needed

LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Operates on 3 AAA Batteries

ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:
Power consumption 1.94W / Batteries AAA
Energizer E92 4.5V dc
LED Specifications: LED 3.0V cc / 648 mA

CERTIFICATES AND COMPLIANCE



EMC, EN62471, FCC



This device complies with part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) This device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Tested according to ANSI/NEMA FL1 Standards. Results based on: Energizer® MAX Alk / E92

PERFORMANCE BENEFITS

- ✓ Up to 4X brighter than standard LED technology
- ✓ Patented optics, delivering exceptional direct and peripheral vision
- ✓ Long runtime

SPECIFICATIONS

Weight Excluding Batteries:

52 Grams / 1.83 Ounces

Dimensions:

59mm x 49mm x 36mm / 2.3" x 1.9" x 1.4"

NUMBER OF OPERATING MODES: 4

| Mode | Lumens (Lm) | Run time (h) | Beam Distance (m) |
|------------|-------------|--------------|-------------------|
| High | 200 | 8:30 | 50 |
| Low (dim.) | 30 | 50 | -- |
| Spot | 145 | 13 | -- |
| Wide | 70 | 30 | -- |

Before using your flashlight, please read all instructions and cautionary marking on the package and the light.

This datasheet contains information specific to products manufactured at the time publication. Contents do not constitute a claim or warranty.

©2018 Energizer