


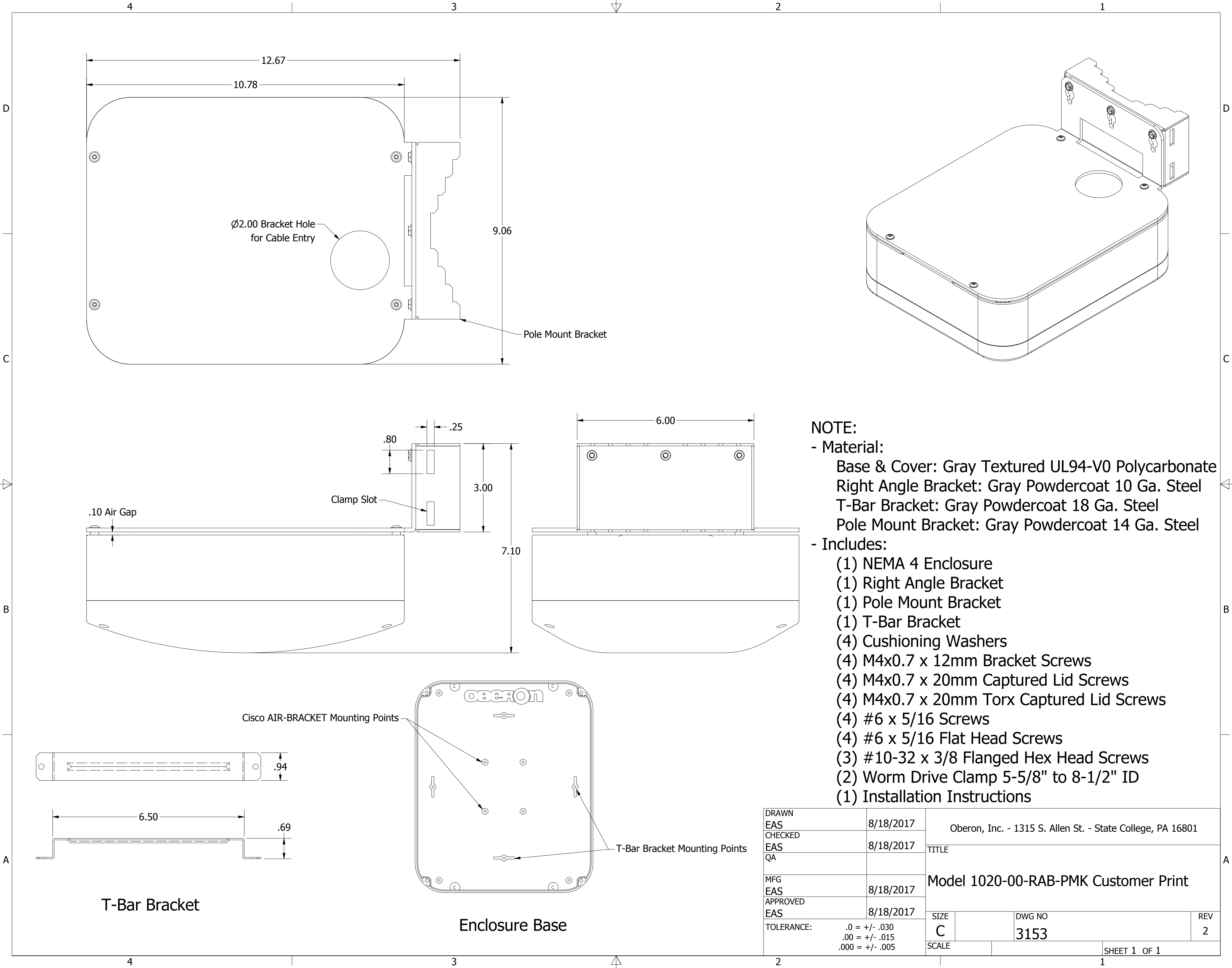

NOTE:

- Material:

Base & Cover: Gray Textured UL94-V0 Polycarbonate
Right Angle Bracket: Gray Powdercoat 10 Ga. Steel
T-Bar Bracket: Gray Powdercoat 18 Ga. Steel
Pole Mount Bracket: Gray Powdercoat 14 Ga. Steel

- Includes:

- (1) NEMA 4 Enclosure
- (1) Right Angle Bracket
- (1) Pole Mount Bracket
- (1) T-Bar Bracket
- (4) Cushioning Washers
- (4) M4x0.7 x 12mm Bracket Screws
- (4) M4x0.7 x 20mm Captured Lid Screws
- (4) M4x0.7 x 20mm Torx Captured Lid Screws
- (4) #6 x 5/16 Screws
- (4) #6 x 5/16 Flat Head Screws
- (3) #10-32 x 3/8 Flanged Hex Head Screws
- (2) Worm Drive Clamp 5-5/8" to 8-1/2" ID
- (1) Installation Instructions

DRAWN	8/18/2017	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
EAS				
CHECKED		TITLE		
EAS	8/18/2017			
QA		Model 1020-00-RAB-PMK Customer Print		
MFG				
EAS	8/18/2017	SIZE		
APPROVED				
EAS	8/18/2017	DWG NO		
TOLERANCE:				
	.0 = +/- .030	3153		
	.00 = +/- .015			
	.000 = +/- .005	SCALE		
		SHEET 1 OF 1		