
 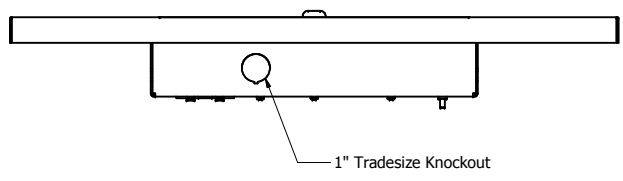

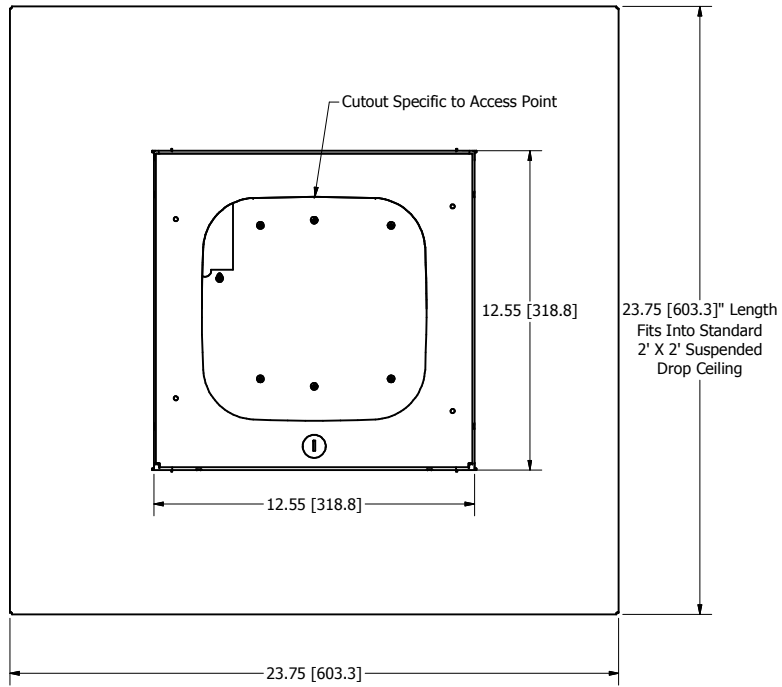
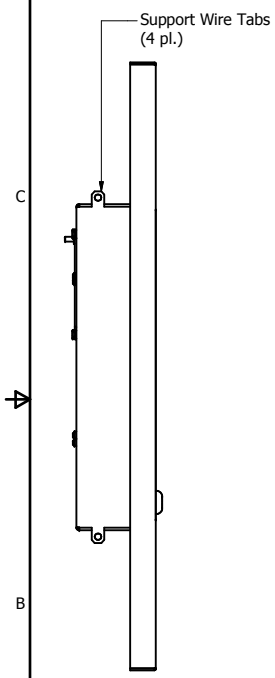


REVISION HISTORY				
ZONE	REV	DESCRIPTION	DATE	APPROVED
All	1	Released	6/5/2018	ATK

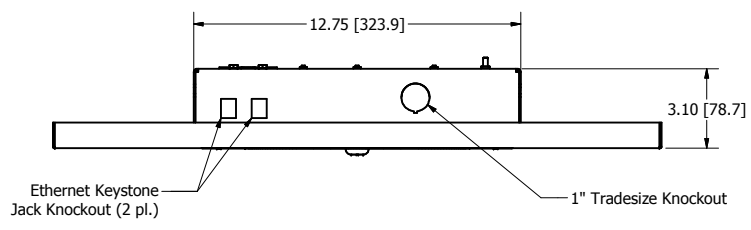

**NOTES:**

- UL Listed NWIN: File No. E348543
- Weight: 14 lbs. [6.5 Kg]
- Material: 16 Ga. Aluminum Backbox  
14 Ga. White Powder Coated Steel Door  
12 Ga. White Powder Coated Steel Flange
- Includes: (1) Conduit Fitting  
(1) Fire Foam Grommet  
(4) Support Wire



DRAWN	6/5/2018	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED		TITLE		
MDA	6/5/2018	Model 1077 Series - Customer Print		
QA				
MFG				
MDA	6/5/2018			
APPROVED				
MDA	6/5/2018			
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005	SIZE	DWG NO	REV
		C	Model1077	1
		SCALE	SHEET 1 OF 2	

Please specify configuration when ordering:

1077 - \_\_\_\_\_ - \_\_\_\_\_

BASE - AP DOOR - TILE TYPE  
 (see Configurations) T for tegular flange,  
 leave blank for lay-in)



### STANDARD "LAY-IN" FLANGE STYLE

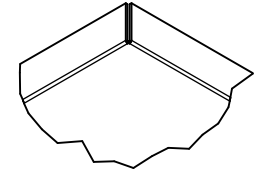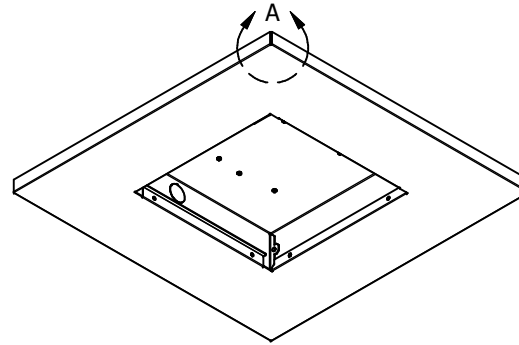

DETAIL A  
SCALE 1:2

Configuration Table				
MODEL NUMBER	BASE	AP DOOR	TILE TYPE	ACCESS POINT
1077-AP205	1077	AP205		Aruba AP205
1077-AP205-T	1077	AP205	Tegular (T)	Aruba AP205
1077-AP215	1077	AP215		Aruba AP215
1077-AP215-T	1077	AP215	Tegular (T)	Aruba AP215
1077-AP225	1077	AP225		Aruba AP225
1077-AP225-T	1077	AP225	Tegular (T)	Aruba AP225
1077-AP325	1077	AP325		Aruba AP325
1077-AP325-T	1077	AP325	Tegular (T)	Aruba AP325
1077-AP335	1077	AP335		Aruba AP335 or AP345
1077-AP335-T	1077	AP335	Tegular (T)	Aruba AP335 or AP345
1077-CCOAP	1077	CCOAP		Cisco 2600, 2700, 3500, 3600, 3700 Series APs
1077-CCOAP-T	1077	CCOAP	Tegular (T)	Cisco 2600, 2700, 3500, 3600, 3700 Series APs
1077-CCOAP3800	1077	CCOAP3800		Cisco 2800, 3800 Series APs
1077-CCOAP3800-T	1077	CCOAP3800	Tegular (T)	Cisco 2800, 3800 Series APs
1077-COAP4800	1077	COAP4800		Cisco 4800 Series APs
1077-COAP4800-T	1077	COAP4800	Tegular (T)	Cisco 4800 Series APs
1077-CP	1077	CP		General Purpose, Works With Most APs
1077-CP-T	1077	CP	Tegular (T)	General Purpose, Works With Most APs
1077-WA	1077	WA		General Purpose, Works With Most APs
1077-WA-T	1077	WA	Tegular (T)	General Purpose, Works With Most APs
1077-ND	1077	ND		N/A (No Door Included)
1077-ND-T	1077	ND	Tegular (T)	N/A (No Door Included)

### "-T" TEGULAR FLANGE STYLE

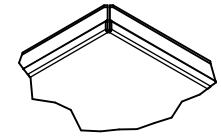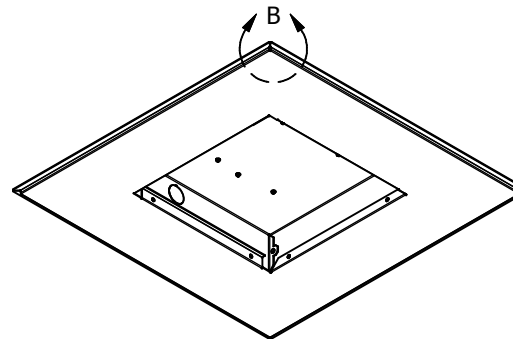

DETAIL B  
SCALE 1:2

DRAWN	MDA	6/5/2018	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED	MDA	6/5/2018	TITLE		
QA			Model 1077 Series - Customer Print		
MFG	MDA	6/5/2018	SIZE	DWG NO	REV
APPROVED	MDA	6/5/2018	C	Model1077	1
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005		SCALE	SHEET 2 OF 2	