



STI Steel Web Stoppers®



STI-9605

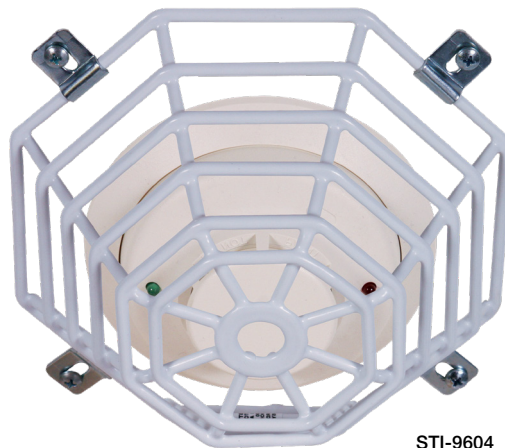

STI-9604

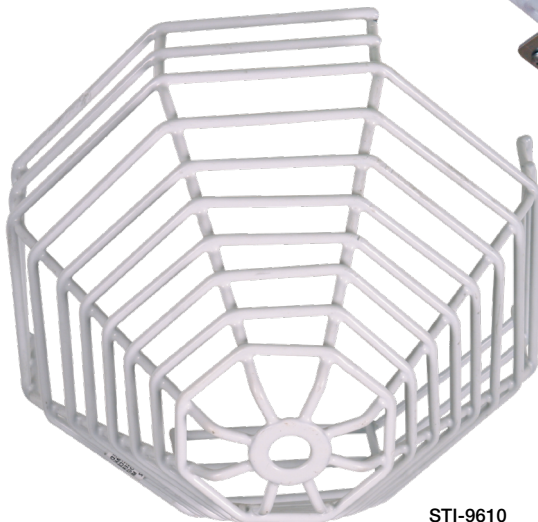

STI-9610

PRODUCT OVERVIEW

UL Listed Protectors for areas where abuse to smoke detectors is severe. Patented (D368,670) web-like octagon shape of heavy-duty coated steel wire makes them extremely difficult to break. They are constructed of heavy-duty steel wire with corrosion resistant plastic coating or heavy-duty stainless steel wire. Together, they cover virtually every smoke detector model available. These Steel Web Stoppers are backed by a three year guarantee against breakage in normal use. Installation and servicing are easy with models for both flush and surface mounting. Highly recommended for areas where abuse to smoke detectors is severe.

KEY FEATURES

General Information

- UL Listed Protectors for areas where abuse to smoke detectors is severe.
- Three year guarantee against breakage in normal use.

Design

- Models to fit virtually all smoke detectors available.
- Steel Web Stoppers have corrosion resistant plastic coating (stainless steel models have no coating).

Construction

- Patented (D368,670) web-like octagon shape of heavy-duty coated steel wire makes them extremely difficult to break.

Installation

- Fast and easy installation.
- Simple removal for servicing of devices.

Options

- May be spray painted once prior to installation to match decor.
- Stainless steel versions available for flush or surface mount.

STI Steel Web Stoppers®

Dimensions and Technical Information

MODELS AVAILABLE

STI-9601	Steel Web Stopper, low profile - Flush mount
STI-9601-SS	Steel Web Stopper, low profile - Flush mount in a stainless steel finish
STI-9602	Steel Web Stopper, low profile - Surface mount
STI-9604	Steel Web Stopper for smoke detectors - Flush mount
STI-9604-SS	Steel Web Stopper for smoke detectors - Flush mount in a stainless steel finish
STI-9605	Steel Web Stopper for smoke detectors - Surface mount
STI-9605-SS	Steel Web Stopper for smoke detectors - Surface mount in a stainless steel finish
STI-9606	Steel Web Stopper for smoke detectors - Flush mount
STI-9609	Steel Web Stopper, high profile - Flush mount
STI-9609-SS	Steel Web Stopper, high profile - Flush mount in a stainless steel finish
STI-9610	Steel Web Stopper, high profile - Surface mount
STI-9712	Steel Web Stopper for photoelectric smoke detector - Surface mount
STI-9713	Steel Web Stopper for photoelectric smoke detector - Flush mount

IMPORTANT NOTICE

STI offers other models of Steel Web Stoppers to cover smoke beam detectors, PIRs, bells, clocks, exit signs and similar devices. For additional information, please contact your distributor or Safety Technology International Ltd.

*NB Cage sizes may vary from -5 to +5 millimetres

TESTING APPROVALS


It has been tested and/or listed by:

STI-9601 - STI-9610 Series UL Listing

- Underwriter Laboratories No. S3504 for any UL Listed detector, does not require any sensitivity adjustment.
- California State Fire Marshal No. 7300-1416:100
- MEA approved #49-00-E

STI-9713 UL Listing

- Underwriter Laboratories No. S3504 for specific detectors listed below (manufactured after June 1, 2004): ADT 2951ADT, EST 2251FB, FCI ASD-PL2, Fire-Lite SD355, Gamewell SS-P, Honeywell TC806B1076, JCI 2951J, Mircom MIX-2251B, Notifier FSP-851, Secutron MRI-2251B, System Sensor 2251B

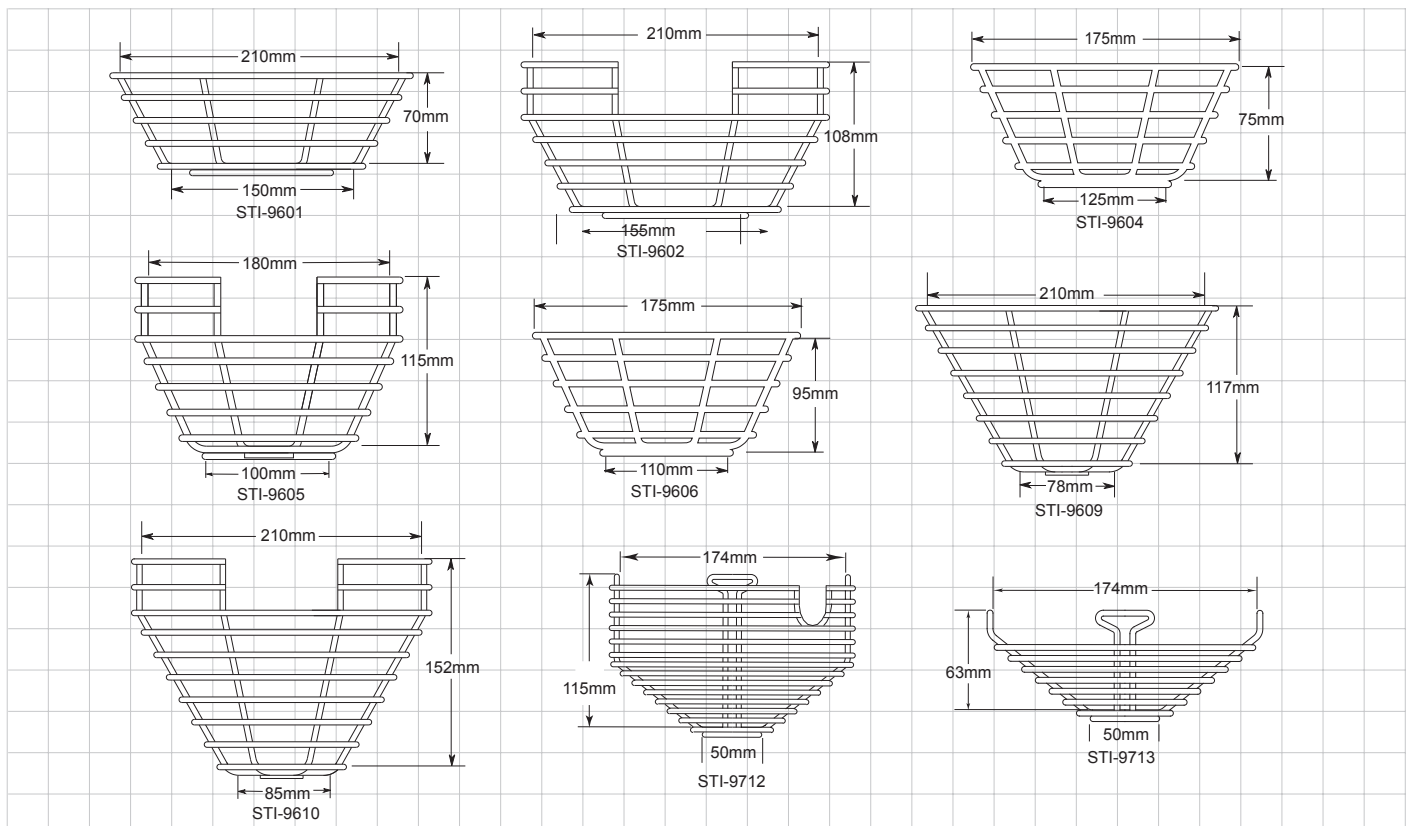

**Safety Technology
International**

Taylor House
34 Sherwood Road
Bromsgrove
Worcestershire
B60 3DR, England

Tel: +44 (0)1527 520 999
Fax: +44 (0)1527 501 999
info@sti-emea.com
www.sti-emea.com

2306 Airport Road
Waterford, Michigan
48327, USA

Tel: 248-673-9898
Fax: 248-673-1246
Toll-free: 800-888-4784
info@sti-usa.com
www.sti-usa.com