



- Tractrix® Horn loaded for clear sound in any location
- Front access, high quality multi-tap transformer with 8-ohm bypass
- Tile bridge included
- For pendant application use with Pendant Housing KPH-800




IC-800-T HIGH OUTPUT, FULL-RANGE 8" 2-WAY

FREQUENCY RESPONSE¹ (+/- 4 dB)	49 Hz - 20 kHz
POWER HANDLING²	150 watts RMS (27V) 600 watts peak*
MAXIMUM SPL³	111 dB 117 dB peak
SENSITIVITY⁴	92 dB
NOMINAL IMPEDANCE	6.5 ohm*
TWEETER	1" (2.54cm) titanium diaphragm compression driver
HIGH FREQUENCY HORN	75° Tractrix® Horn
WOOFER	8" (20.32cm) woofer
TAP SETTINGS	12.5 watts, 25 watts, 50 watts, 100 watts @ 70V 100 watts, 50 watts, 25 watts @ 100V
ENCLOSURE TYPE	Bass-reflex via Tractrix® port
WEIGHT	21 lbs. (9.5kg)
CUTOUT DIMENSIONS	12.625" (32.1cm) diameter
MOUNTING DEPTH	12.75" (32.4cm)
OVERALL DEPTH	13.125" (33.3cm)
OVERALL WIDTH	14.15" (35.9cm) diameter
THRU HOLE WIDTH	12.5" (31.75cm)
FINISHES	White
WIRE GAUGE ACCOMODATED	14 AWG
PRE-CONSTRUCTION MUD RING	061347

SHIPPING QUANTITY: Single
SHIPPING WEIGHT: 26.3 lbs

PART NUMBER
1062347 (White)

NOTES:

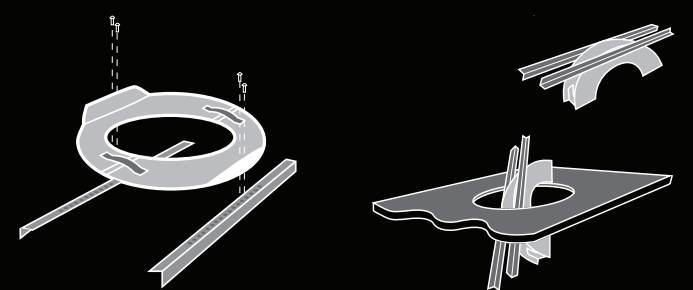

MAKE IT EASY FOR YOURSELF

All Klipsch IC Series Speakers are shipped complete with a foldable tile bridge for installation in suspended ceilings or wherever additional reinforcement of ceiling material is required.



- Unique transformerless 4 voice coil, 70V/100V capability
- Single-input 4-ohm or dual-input 8-ohm operation
- Tile bridge included
- For pendant application use with Pendant Housing KPH-800



IC-SW-8T2 8" IN-CEILING SUBWOOFER

FREQUENCY RESPONSE¹ (+/- 4 dB)	50 Hz - 130 Hz
POWER HANDLING²	150 watts RMS (27V) 600 watts peak*
MAXIMUM SPL³	111 dB 117 dB peak
SENSITIVITY⁴	92 dB
NOMINAL IMPEDANCE	8 ohm*
WOOFER	8" (20.32cm) woofer and 8" (20.32cm) drone passive radiator
TAP SETTINGS	30 watts, 60 watts @ 70V 60 watts, 120 watts @ 100V
ENCLOSURE TYPE	Bandpass via drone passive radiator
WEIGHT	23 lbs. (10.43kg)
CUTOUT DIMENSIONS	12.625" (32.1cm) diameter
MOUNTING DEPTH	12.75" (32.4cm)
OVERALL DEPTH	13.125" (33.3cm)
OVERALL WIDTH	14.15" (35.9cm) diameter
THRU HOLE WIDTH	12.5" (31.75cm)
FINISHES	White
WIRE GAUGE ACCOMODATED	14 AWG
PRE-CONSTRUCTION MUD RING	061347

SHIPPING QUANTITY: Single
SHIPPING WEIGHT: 26.3 lbs

PART NUMBER
1008722 (White)

NOTES:

* 8 ohm bypass
1 3M, Half-space anechoic
2 AES standard, continuous pink noise, 6dB peaks
3 Calculated at 1M half-space at power handling power input
4 SPL at 1M, half-space anechoic with 2.83 volts input