

Wall Kiosk - Landscape

Fits 40", 42", 43", 46", 47", 48", 49" and 55" Displays
less than 3.5" (89mm) deep


1. Hinged top frame offers easy access to the display and other internal components for easy maintenance and enhanced security
2. Eight-way tool-less adjustment to quickly position display in kiosk window for flush alignment
3. Thermostat controlled circulation fans ensure proper airflow within the kiosk
4. Pre-assembled to simplify installation of the entire solution
5. Supports wide range of aesthetic options including glass/acrylic, multiple colors, vinyl wraps, etc. to best match environment or promote brand strategy
6. Stand-alone kiosk enclosure or fully integrated with display, media player, power and thermal management, etc.
7. Custom sizes available for smaller and larger displays



Please visit peerless-av.com/en-us/patents for patent information.

For expanded product information and technical data visit peerless-av.com

TECHNICAL DRAWINGS

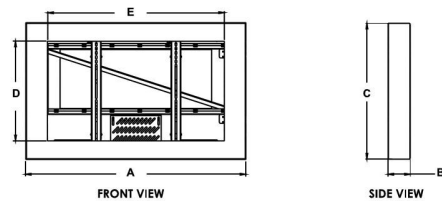

MODEL NO.	DIMENSION "A"	DIMENSION "B"	DIMENSION "C"	DIMENSION "D"	DIMENSION "E"
KIL40-3SD	43.50" (1105mm)	5.45" (139mm)	27.00" (686mm)	19.67" (500mm)	34.97" (888mm)
KIL42-3SD	43.50" (1105mm)	5.45" (139mm)	27.00" (686mm)	20.45" (525mm)	34.72" (883mm)
KIL43-3SD	43.50" (1105mm)	5.45" (139mm)	27.00" (686mm)	21.13" (537mm)	37.59" (955mm)
KIL46-3SD	48.00" (1219mm)	5.45" (139mm)	29.00" (737mm)	22.61" (574mm)	40.20" (1021mm)
KIL47-3SD	48.00" (1219mm)	5.45" (139mm)	29.00" (737mm)	23.10" (587mm)	41.07" (1043mm)
KIL48-3SD	48.00" (1219mm)	5.45" (139mm)	29.00" (737mm)	23.59" (599mm)	41.94" (1065mm)
KIL49-3SD	56.00" (1422mm)	5.45" (139mm)	34.10" (866mm)	24.08" (611mm)	42.82" (1087mm)
KIL55-3SD	56.00" (1422mm)	5.45" (139mm)	34.10" (866mm)	27.03" (686mm)	48.05" (1220mm)

To verify mount compatibility with any display or projector model use MountFinder™ at peerless-av.com.

630-375-5100 | 800-865-2112 | info@peerless-av.com | peerless-av.com

KIOSKS



INDOOR
KIOSKS

MODELS

Universal Models:

For displays 3.5" (89mm) thick

Landscape models:

KIL640(-S)-3SD	40" Displays	Gloss black/Silver
KIL642(-S)-3SD	42" Displays	Gloss black/Silver
KIL643(-S)-3SD	43" Displays	Gloss black/Silver
KIL646(-S)-3SD	46" Displays	Gloss black/Silver
KIL647(-S)-3SD	47" Displays	Gloss black/Silver
KIL648(-S)-3SD	48" Displays	Gloss black/Silver
KIL649(-S)-3SD	49" Displays	Gloss black/Silver
KIL655(-S)-3SD	55" Displays	Gloss black/Silver

DISPLAY ADAPTOR



VESA® Pattern

Universal Models: 200 x 200 up to 600 x 400mm

SPECIFICATIONS

Distance from Wall

5.45" (139mm)



Max Load

75lb (34kg)

Product Dimensions (W x H x D)

KIL640/642/643(-S)-3SD:	43.50" x 27.00" x 5.45" (1105 x 686 x 139mm)
KIL646/647/648/649(-S)-3SD:	48.00" x 29.00" x 5.45" (1219 x 737 x 139mm)
KIL655(-S)-3SD:	56.00" x 34.01" x 5.45" (1422 x 866 x 139mm)

Storage Space (D)

1.56"-2.30" (40-58mm)

Mounting Surfaces

Wood stud, concrete, cinder block and metal stud
(Metal stud accessory required)

Ship Weight

KIL640/642/643(-S)-3SD:	90lb (40kg)
KIL646/647/648/649(-S)-3SD:	100lb (45kg)
KIL655(-S)-3SD:	110lb (50kg)

CERTIFICATIONS



ACCESSORIES

- ACC415:** 4-pack Metal Stud Fastener Kit pg# 226
IBA4-W: Easy Mount Recessed Low Voltage Cable Plate pg# 219
IBA5-W: Recessed Low Voltage Media Plate with Duplex Surge Suppressor pg# 219

Custom Kiosk



HDMI and Component Video Cables
Clear or Non-glare Tempered Glass
Clear or Non-glare Polycarbonate
Logos And Graphics



KioskBuilder™:
Build your own Integrated Kiosk @
kiosks.peerless-av.com



Antimicrobial Protection:
Agion® antimicrobial* finish available to
assist in controlling the spread of infections
Contact Peerless-AV Customer Care for more information.

*Antimicrobial protection is limited to the treated article and does not protect a user against disease causing bacteria. Always clean products thoroughly after each use.