

KIP740/742/743/746/  
747/748/749/755(-S)



**Mounting Pattern**  
200 x 200 up to  
400 x 600mm



**Max Load**  
75lb  
(34kg)

# In-Wall Kiosk Enclosure

Fits 40", 42", 43", 46", 47", 48", 49" and 55" Displays  
up to 3.10" (78mm) Thick

With a profile less than 1" thin, Peerless-AV's In-Wall Kiosk Enclosure offers a sleek solution to display engaging, digital signage content. Complete with extending mount arms and a removable front cover, this kiosk offers easy installation and access to internal components when maintenance is needed. To ensure proper airflow into the kiosk enclosure, a powerful, thermostat controlled fan is included. Available in portrait or landscape orientation, Peerless-AV's In-Wall Kiosk Enclosures are ideal for any indoor application - from hospitality, retail, entertainment venues and more.

- Accommodates displays 3.10" (78mm) thick while still fitting within standard wood stud walls
- VESA® 200 x 200 up to 400 x 600mm compatible
- Thermostat controlled circulation fans ensure proper airflow into the kiosk
- Pre-assembled to simplify installation of the entire solution
- Supports wide range of aesthetic options including glass/acrylic, multiple colors, vinyl wraps, etc. to best match environment or promote brand strategy
- Custom sizes available for smaller and larger displays



## REMOVABLE FRONT COVER & PULL-OUT MOUNT

Allows easy installation and maintenance of display and other internal components

## 8-WAY MICRO ADJUSTMENT

Provides quick vertical, horizontal and depth adjustment to quickly position display in kiosk window for flush alignment



## LOW-PROFILE DESIGN

Extends 1" (25mm) away from the wall which meets the Americans with Disabilities Act (ADA)

Portrait Model



Landscape Models Available



**RoHS**  
2009/1000/EC



Please visit [peerless-av.com/en-us/patents](http://peerless-av.com/en-us/patents) for patent information.

✉ [info@peerless-av.com](mailto:info@peerless-av.com)

🌐 [peerless-av.com](http://peerless-av.com)

**peerless-AV**<sup>®</sup>  
Driving Technology Through Innovation

## Model Numbers

**WARRANTY: 5 years on metal components, 1 year on electronic components**

### Portrait Models:

**KIP740(-S)** In-Wall Kiosk Enclosure fits 40" Displays up to 3.10" (78mm) Thick  
**KIP742(-S)** In-Wall Kiosk Enclosure fits 42" Displays up to 3.10" (78mm) Thick  
**KIP743(-S)** In-Wall Kiosk Enclosure fits 43" Displays up to 3.10" (78mm) Thick  
**KIP746(-S)** In-Wall Kiosk Enclosure fits 46" Displays up to 3.10" (78mm) Thick

**KIP747(-S)** In-Wall Kiosk Enclosure fits 47" Displays up to 3.10" (78mm) Thick  
**KIP748(-S)** In-Wall Kiosk Enclosure fits 48" Displays up to 3.10" (78mm) Thick  
**KIP749(-S)** In-Wall Kiosk Enclosure fits 49" Displays up to 3.10" (78mm) Thick  
**KIP755(-S)** In-Wall Kiosk Enclosure fits 55" Displays up to 3.10" (78mm) Thick

## Product Specifications

	DIMENSIONS (W x H x D)	PRODUCT WEIGHT	LOAD CAPACITY	FINISH	AVAILABLE COLORS
<b>KIP740/742/743(-S)</b>	28.91" x 45.41" x 5.15" (734x1153 x 131mm)	79lb (35kg)	75lb (34kg)	Powder Coat	KIP740/742/743/746/747/748/749/755: Gloss Black KIP740-S/742-S/743-S/746-S/747-S/748-S/749-S/755-S: Silver
<b>KIP746/747/748(-S)</b>	31.85" x 50.40" x 5.15" (809 x 1280 x 131mm)	87lb (39kg)			
<b>KIP749/755(-S)</b>	35.35" x 57.90" x 5.15" (898 x 1471 x 131mm)	97lb (44kg)			

## Package Specifications

	PACKAGE SIZE (W x H x D)	PACKAGE SHIP WEIGHT	PACKAGE UPC CODE		PACKAGE CONTENTS	UNITS IN PACKAGE
<b>KIP740/742/743(-S)</b>	50.00" x 36.00" x 8.00" (1270 x 914 x 203mm)	90lb (41kg)	KIP740: 735029307822	KIP740-S: 735029307839	Kiosk & Display Mounting Hardware	1
<b>KIP746/747/748/749(-S)</b>	54.00" x 39.00" x 8.00" (1371 x 990 x 203mm)	100lb (45kg)	KIP742: 735029307679	KIP742-S: 735029307846		
			KIP743: 735029315773	KIP743-S: 735029315780		
<b>KIP749/755(-S)</b>	62.00" x 43.00" x 8.00" (1574 x 1092 x 203mm)	110lb (50kg)	KIP746: 735029308010	KIP746-S: 735029308027		
			KIP747: 735029308034	KIP747-S: 735029308041		
			KIP748: 735029308058	KIP748-S: 735029308065		
			KIP749: 735029318729	KIP749-S: 735029318804		
			KIP755: 735029308126	KIP755-S: 735029308133		

## Accessories

### KioskBuilder™:

Build your own Integrated Kiosk @ [kiosks.peerless-av.com](http://kiosks.peerless-av.com) including integration services, flat panel display, media player, content management software, power protection, thermal management, display protection, vinyl graphics, etc.




### Agion antimicrobial protection:

Agion® antimicrobial\* finish available to assist in controlling the spread of infections. Contact Peerless-AV Customer Care for more information.

\*Antimicrobial protection is limited to the treated article and does not protect a user against disease causing bacteria. Always clean products thoroughly after each use.

All dimensions = inch (mm)

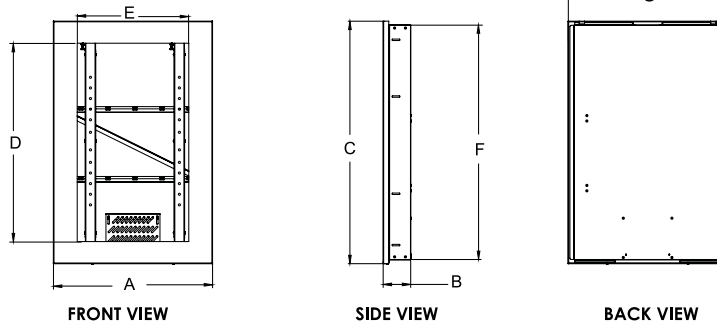

MODEL NO.	DIMENSION "A"	DIMENSION "B"	DIMENSION "C"	DIMENSION "D"	DIMENSION "E"	DIMENSION "F"	DIMENSION "G"
<b>KIP740</b>	29.47" (749mm)	5.05" (128mm)	44.89" (1140mm)	34.97" (888mm)	19.67" (500mm)	43.50" (1105mm)	27.25" (692mm)
<b>KIP742</b>	29.47" (749mm)	5.05" (128mm)	44.89" (1140mm)	36.72" (933mm)	20.65" (525mm)	43.50" (1105mm)	27.25" (692mm)
<b>KIP743</b>	29.47" (749mm)	5.05" (128mm)	44.89" (1140mm)	37.59" (955mm)	21.13" (537mm)	43.50" (1105mm)	27.25" (692mm)
<b>KIP746</b>	32.48" (825mm)	5.05" (128mm)	49.65" (1261mm)	40.20" (1021mm)	22.61" (574mm)	48.25" (1226mm)	30.25" (768mm)
<b>KIP747</b>	32.48" (825mm)	5.05" (128mm)	49.65" (1261mm)	41.07" (1043mm)	23.10" (587mm)	48.25" (1226mm)	30.25" (768mm)
<b>KIP748</b>	32.48" (825mm)	5.05" (128mm)	49.65" (1261mm)	41.94" (1065mm)	23.59" (599mm)	48.25" (1226mm)	30.25" (768mm)
<b>KIP749</b>	35.92" (912mm)	5.05" (128mm)	57.15" (1452mm)	42.82" (1088mm)	24.08" (611mm)	55.75" (1416mm)	33.75" (857mm)
<b>KIP755</b>	35.92" (912mm)	5.05" (128mm)	57.15" (1452mm)	48.05" (1220mm)	27.03" (686mm)	55.75" (1416mm)	33.75" (857mm)

## Architect Specifications

The In-Wall Kiosk Enclosure shall be a Peerless-AV model KIP740(-S), 742(-S), 743(-S), 746(-S), 747(-S), 748(-S), 749(-S) or 755(-S) and shall be located where indicated on the plans. Assembly and installation shall be done according to instructions provided by the manufacturer.

Visit [peerless-av.com](http://peerless-av.com) to see the complete line of AV solutions from Peerless-AV, including outdoor displays, wireless, kiosks, digital audio, display mounts, projector mounts, carts/stands, and a full assortment of accessories.

**Peerless-AV**  
 2300 White Oak Circle  
 Aurora, IL 60502 USA  
**(800) 865-2112**  
**(630) 375-5100**  
**Fax: (800) 359-6500**

**Peerless-AV EMEA**  
 Unit 3 Watford Interchange  
 Colonial Way, Watford  
 Herts, WD24 4WP  
 United Kingdom  
**+44 (0) 1923 200100**  
**Fax: +44 (0) 1923 200101**

**Peerless-AV Latin America**  
 Ave de las Industrias 413  
 Parque Industrial Escobedo  
 Escobedo, N.L.,  
 Mexico 66062  
**+52 (81) 8384-8300**  
**Fax: +52 (81) 8384-8360**

