

Ultra-Slim Portrait Kiosk

Fits most 40", 42", 43", 46", 47", 48", 49", 50", 55" and 65" Displays
less than 3.50" (88mm) deep


1. Designed with architectural steel and a 3/8" steel base plate that provides stability, strength and corrosion resistance
2. Whisper-quiet, thermostat controlled exhaust fans ensure internal components operate at the manufacturer's stated temperature
3. Six outlet, UL- and cUL-approved surge suppressor with 6' cord to protect voltage-sensitive components from damaging power surges
4. Internal micro-adjustments allow for quick positioning of display within the kiosk window for flush alignment
5. Internal component tray to store media player and cables neatly for a professional finish
6. Combination locks allow access only to the parts requiring maintenance, with no threat of lost keys
7. High-performance, premium powder coat finish protects the unit and extends the product lifespan
8. Stand-alone or fully integrated with display, audio components, media player and input components
9. Supports a wide range of aesthetic options including multiple colors, vinyl wraps, etc. to best match the environment or promote brand strategy



Please visit peerless-av.com/en-us/patents for patent information.

For expanded product information and technical data visit peerless-av.com

TECHNICAL DRAWINGS

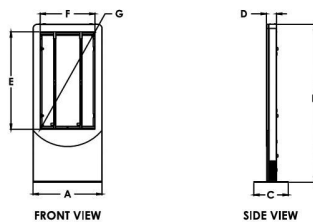

MODEL NO.	DIMENSION "A"	DIMENSION "B"	DIMENSION "C"	DIMENSION "D"	DIMENSION "E"	DIMENSION "F"	DIMENSION "G"
KIPC3540	28.00" (711mm)	72.20" (1834mm)	17.00" (432mm)	5.00" (127mm)	34.98" (888mm)	19.67" (500mm)	40.13" (1019mm)
KIPC3542	28.00" (711mm)	72.20" (1834mm)	17.00" (432mm)	5.00" (127mm)	36.72" (933mm)	20.65" (525mm)	42.13" (1070mm)
KIPC3543	28.00" (711mm)	72.20" (1834mm)	17.00" (432mm)	5.00" (127mm)	37.59" (955mm)	21.13" (537mm)	43.13" (1095mm)
KIPC3546	31.00" (787mm)	72.20" (1834mm)	17.00" (432mm)	5.00" (127mm)	40.20" (1021mm)	22.61" (574mm)	46.13" (1171mm)
KIPC3547	31.00" (787mm)	72.20" (1834mm)	17.00" (432mm)	5.00" (127mm)	41.07" (1043mm)	23.10" (587mm)	47.13" (1197mm)
KIPC3548	31.00" (787mm)	72.20" (1834mm)	17.00" (432mm)	5.00" (127mm)	41.96" (1066mm)	23.57" (599mm)	48.13" (1222mm)
KIPC3549	34.00" (864mm)	78.20" (1986mm)	17.00" (432mm)	5.00" (127mm)	42.76" (1087mm)	24.15" (613mm)	49.13" (1247mm)
KIPC3550	34.00" (864mm)	78.20" (1986mm)	17.00" (432mm)	5.00" (127mm)	43.66" (1109mm)	24.63" (625mm)	50.13" (1273mm)
KIPC3555	34.00" (864mm)	78.20" (1986mm)	17.00" (432mm)	5.00" (127mm)	48.05" (1220mm)	27.03" (687mm)	55.13" (1400mm)

To verify mount compatibility with any display or projector model use MountFinder™ at peerless-av.com.

630-375-5100 | 800-865-2112 | info@peerless-av.com | peerless-av.com

KIOSKS



INDOOR
KIOSKS

MODELS

Universal Models:

For displays less than 3.50" (88mm) deep

KIPC3540(-S)	40" Displays	Gloss black/Silver
KIPC3542(-S)	42" Displays	Gloss black/Silver
KIPC3543(-S)	43" Displays	Gloss black/Silver
KIPC3546(-S)	46" Displays	Gloss black/Silver
KIPC3547(-S)	47" Displays	Gloss black/Silver
KIPC3548(-S)	48" Displays	Gloss black/Silver
KIPC3549(-S)	49" Displays	Gloss black/Silver
KIPC3550(-S)	50" Displays	Gloss black/Silver
KIPC3555(-S)	55" Displays	Gloss black/Silver
KIPC3565(-S)	65" Displays	Gloss black/Silver

SPECIFICATIONS



Max Load

75lb (34kg)

Product Dimensions (W x H x D)

KIPC3540/3542/3543(-S):	28.00" x 72.20" x 17.00" (711 x 1834 x 432mm)
KIPC3546/3547/3548(-S):	31.00" x 72.20" x 17.00" (787 x 1834 x 432mm)
KIPC3549/3550/3555(-S):	34.00" x 78.20" x 17.00" (864 x 1986 x 432mm)
KIPC3565(-S):	40.00" x 86.40" x 19.50" (1016 x 2194 x 495mm)

Storage Space (W x H x D)

KIPC3540/3542/3543(-S):	27.00" x 15.00" x 3.70" (635 x 381 x 94mm)
KIPC3546/3547/3548(-S):	30.00" x 15.00" x 3.70" (762 x 381 x 94mm)
KIPC3549/3550/3555(-S):	33.00" x 15.00" x 3.70" (838 x 381 x 94mm)
KIPC3565(-S):	39.00" x 15.00" x 3.70" (990 x 381 x 94mm)

Mounting Surfaces

Flat, solid floor surfaces

Ship Weight

KIPC3540(-S):	213lb (96kg)
KIPC3542(-S):	212lb (96kg)
KIPC3543(-S):	211lb (96kg)
KIPC3546(-S):	182lb (83kg)
KIPC3547(-S):	181lb (82kg)
KIPC3548(-S):	181lb (82kg)
KIPC3549(-S):	244lb (111kg)
KIPC3550(-S):	243lb (110kg)
KIPC3555(-S):	239lb (101kg)
KIPC3565(-S):	265lb (120kg)

CERTIFICATIONS



ACCESSORIES

Custom Kiosk



HDMI and Component Video Cables
Stereo Speaker System with Amplifier
Logitech Webcameras
Clear or Non-glare Tempered Glass
Clear or Non-glare Polycarbonate
Logos And Graphics



KioskBuilder™:
Build your own integrated Kiosk @
kiosks.peerless-av.com



Antimicrobial Protection:
Agion® antimicrobial* finish
available to assist in controlling
the spread of infections

Contact Peerless-AV Customer Care
for more information.

*Antimicrobial protection is limited to the treated article and does not protect a user against disease causing bacteria. Always clean products thoroughly after each use.