

PanZone® Consolidation Point Box

specifications

The Consolidation Point Box shall be used with low profile underfloor, in-ceiling and wall mount applications. The Consolidation Point Box shall be capable of managing MiniCom® modular panels used with snap in modular faceplates and 19" patch panels. Panels shall be removable for quick installation and reconfigurations. The Consolidation Point Box shall have a removable cover to protect connection points and shall have a foam seal around cable entry and exit points to protect from excess dust and debris. The Consolidation Point Box shall be wall mountable, as well as mountable underfloor and in-ceiling. The 24 and 48 port consolidation point box shall accommodate MiniCom®, NetKey®, QuickNet™, and/or Fiber applications.



technical information

Mounting Option: Vertical or horizontal wall mounting, low profile raised floor system, and in-ceiling applications. The 6 and 12 port boxes can also be mounted in workspaces. Internal mounting holes and optional external mounting brackets are included.

Packaging:

| | |
|----------|---|
| CPB6BL: | Includes base, cover, modular panels, Snap-In MiniCom® Faceplate, and external mounting brackets. |
| CPB12BL: | Includes base, cover, modular panels, Snap-In MiniCom® Faceplate, and external mounting brackets. |
| CPB24BL: | Includes base, cover, and external mounting brackets. Patch Panel not included. |
| CPB48BL: | Includes base, cover, and external mounting brackets. Patch Panel not included. |

| Part Number | Port Capacity | Height In. (mm) | Width In. (mm) | Depth In. (mm) |
|-------------|---------------|-----------------|-----------------|----------------|
| CPB6BL | 6 | 2.48" (63) | 7" (177.8) | 6.99" (177.5) |
| CPB12BL | 12 | 2.48" (63) | 11.30" (287) | 7.15" (181.6) |
| CPB24BL | 24 (1 RU) | 1.93" (49.1) | 20.15" (511.18) | 12.15" (308.6) |
| CPB48BL | 48 (2 RU) | 3.74" (95) | 20.15" (511.18) | 12.15" (308.6) |

key features and benefits

| | |
|--|--|
| Removable Modular Panels and Patch Panels | Quick drop-in panel design allows for time savings on installation, termination, and reconfiguration and allows for easier access to all ports. This feature eliminates unnecessary network interruptions when connection changes are needed. |
| Versatility in Configurations | Accepts interchangeable modular patch panels for use with MiniCom®, NetKey®, QuickNet™, or Fiber which creates a consistent specification for a variety of applications. The Consolidation Point Box is also mountable in-ceiling, underfloor, on a wall or under desks. |
| Protection of Investment | The removable cover and foam seal around openings protect cable connections by preventing dust and debris from tampering with connections. |
| Large Cable Entry Points | Allows for optimum cable capacity and maintains cable bend radius to ensure top network performance. |

applications

The PanZone® Consolidation Point Box provides a low-cost, easy to install solution and provides a point of connection and configuration within the permanent link for the user to allow interconnection/cross connection to a network service or device. The Consolidation Point Box provides accessibility and flexibility to reconfigure cable runs to meet frequently changing organizational requirements and reduces network downtime when these reconfigurations happen. The Consolidation Point Box allows for quick modifications. We offer the ability to use a modular panel (included) in our 6 and 12 port box

and a standard 19" patch panel (sold separately) in the 24 and 48 port boxes. In each Consolidation Point Box, the panels can be completely removed which allows for quick and easy termination and installation. These panels are interchangeable for use with MiniCom®, NetKey®, QuickNet™, and Fiber. The optional strain relief bar can be installed to support and manage cable bundles. The Consolidation Point Box is versatile in where and how it can be mounted. Each box can be mounted in ceiling or underfloor, but also can be mounted to the wall or under workspaces.

PanZone® Consolidation Point Box

| | |
|--|----------|
| 6 Port Consolidation Point Box: | CPB6BL |
| 12 Port Consolidation Point Box: | CPB12BL |
| 24 Port (1 RU) Consolidation Point Box: | CPB24BL |
| 48 Port (2 RU) Consolidation Point Box: | CPB48BL |
| Strain Relief Bar for 24 and 48 Port Boxes: | SRB19BLY |

MiniCom® Patch Panels and Modules


 

| | |
|--|-------------|
| MiniCom® 24 Port Modular Patch Panel: | CPP24FMWBLY |
| MiniCom® 48 Port Modular Patch Panel: | CPP48FMWBLY |
| MiniCom® 6 Port Snap-In Faceplate: | CFPLM6BLY |

QuickNet™ Patch Panels





| | |
|--|---------|
| QuickNet™ 24 Port Patch Panel for Pre-term Cassettes: | QPP24BL |
| QuickNet™ 48 Port High Density 1 RU Patch Panel: | QPP24BL |

PanZone® Consolidation Point Box





dimensions

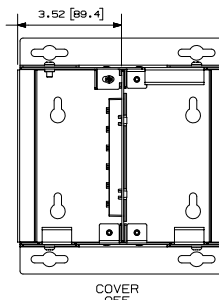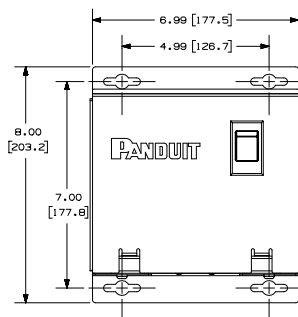





CPB6BL
6 PORT CONSOLIDATION POINT BOX

 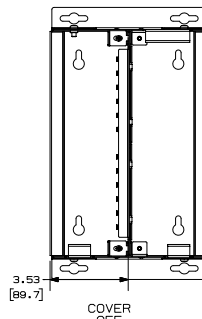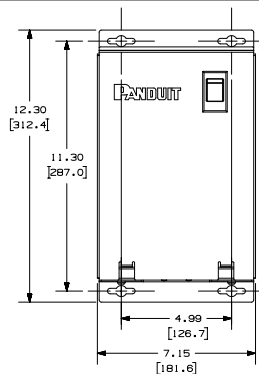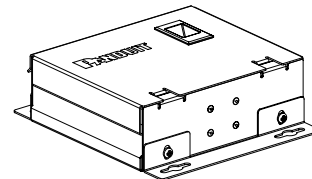


CPB12BL
12 PORT CONSOLIDATION POINT BOX

 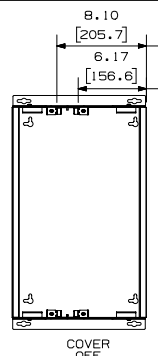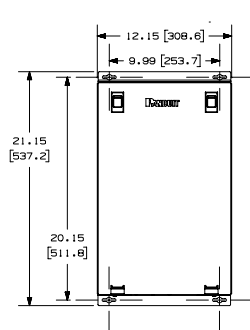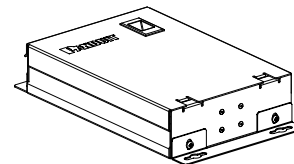

CPB24BL
24 PORT CONSOLIDATION POINT BOX

 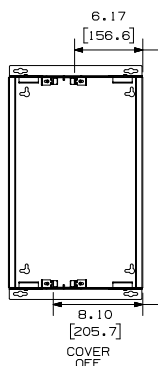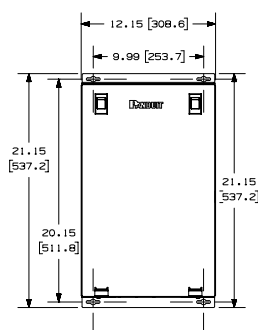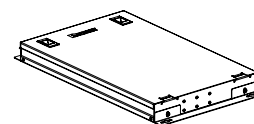

CPB48BL
48 PORT CONSOLIDATION POINT BOX

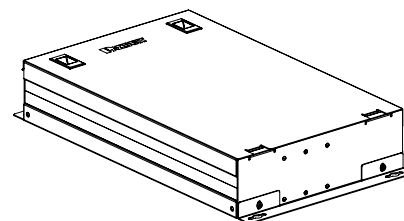

Dimensions are in inches. [Dimensions in brackets are metric].

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

PANDUIT®

For more information
Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

© 2019 Panduit Corp.
ALL RIGHTS RESERVED.
Printed in the U.S.A.
FBSP167--WW-ENG
12/2019