



15 Inch / Projected Capacitive Touch Monitor

D15ZX-AV-45P0

DESKTOP TOUCH



Gvision manufactures a variety of desktop and point of sale (POS) monitors. This 15" touch screen monitors are available with 10-point multi touch projected capacitive (PCAP) screens



10-Points
Touch



DVI-D Digital
Input



HDMI Digital
Input



VGA Analog
Input



USB B-Type
Touch



IP65
Protected

 


LED
Backlight
Unit



3-Years
Warranty

15-Inch PCAP Touch Screen Monitor



FEATURES

- 15-Inch Screen Size
- 1024 x 768 Resolution
- Video signal: **VGA / DVI / VGA**
- **IP65** on the Front (Optional)
- **Zero Pressure** Touch Activation
- **LED** Backlight Unit
- **Metal Enclosure** Material


INPUT INTERFACE



Multi Inputs

Gvision's Desktop/ POS monitor supports both digital DVI, HDMI and analog VGA inputs to use as normal office desktop monitor. Also, it support USB-Type B to use touch function as well.

DIMENSIONS

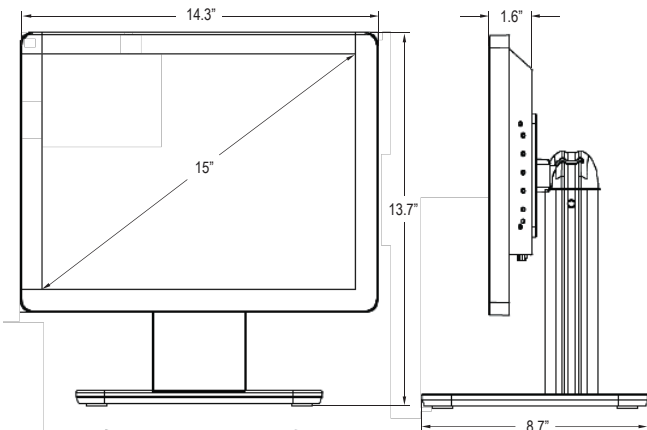

SPECIFICATIONS

DISPLAY	D15ZX-AV-4 5P0
Screen Size	15 In
Resolution	1024 x 768
Backlight	LED
Aspect Ratio	4 : 3
Viewing Angle	160° / 130°
Response Time	8ms
Brightness	300cd/m ²
Contrast Ratio	700 : 1
Color Depth	16.7 M
Display Area (mm)	304.1 x 228.1mm
INTERFACE	
DVI	1
HDMI	1
VGA (15 Pin D-Sub)	1
TOUCH TECHNOLOGY	
Glass	2mm Tempered Glass
P-Cap Type	10 Points Projective Capacitance Touch
FEATURES	
Support OS	Windows / Linux
AUDIO	
Speakers	Option
CABINET	
Material	Metal
POWER	
Consumption	< 12W
Electrical Ratings	12V DC ± 5% (AC 100V ~ 240V, 50/60Hz)
TEMPERATURE	
Operating	32° F ~ 104° F (0° C ~ 40° C)
DIMENSIONS (WxHxD)	
Inch (in) w/ Stand	14.3 x 13.7 x 8.7
Millimeter (mm) w/ Stand	362.4 x 348.4 x 220
WEIGHT	
Net Weight	11 lbs (5kg)
VESA™	
Mount Size (mm)	100 x 100

Specifications subject to change without any notice