




## Features

- Low Noise Compact Design
- Intel® Core i7 Series Processor
- Dual-Purpose Recording & Live Viewing
- Dedicated SSD Boot Drive
- Up to 20TB Internal Video Storage
- Designed for 24/7 Video Recording
- Dual SATA drive configurations available
- Pre-Loaded Windows 10 Enterprise
- Quick Setup Wizard for simple VMS deployment

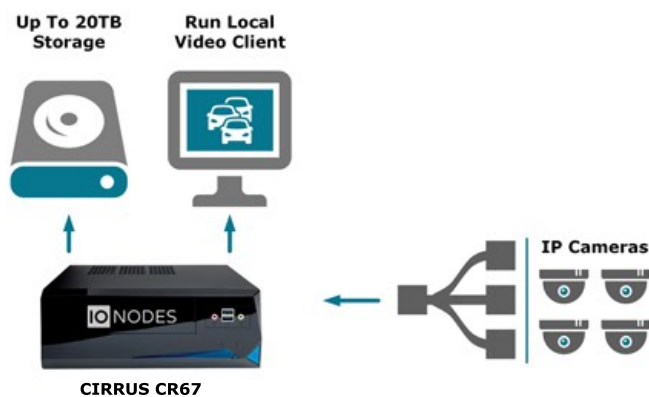

# CR67

## Compact All-In-One NVR Appliance

The CIRRUS CR67 compact video server (NVR) has been designed for performance and peace of mind. Offering recording capacity up to 20TB, the CR67 offers key features such as Quick Setup Wizard, high performance INTEL processor, dedicated SSD boot drive (OS), dual SATA drives and Gigabit Ethernet.

## Cloud access from any device

The IONODES Video Cloud allows you to access live video from anywhere, anytime, using your favorite iOS or Android device or from any computer through the web portal. Our cloud services also allow you to receive realtime event alerts for motion detection and camera status changes. Event video is stored on secure cloud storage and can easily be accessed remotely and shared.



## Built to last

High performance solid state boot drive, internal realtime hardware and software watchdogs and fully recoverable operating system image extends the reliability of your critical installations.

## Pre-loaded VMS platforms

AVIGILON  
THE BEST EVIDENCE™

AXIS  
COMMUNICATIONS

exacq®  
Technologies

Genetec

milestone



# CR67 Specifications

## Compact All-In-One NVR Appliance

### System

Processor	Intel® Core i7-9700 (passmark: 15951) 12M Cache, up to 4.70 GHz
Memory	8GB DDR4
Network	2 x 10/100/1000 Base-T Ethernet port(s) RJ45
USB	4 x USB 3.0 2 x USB 2.0
Video Outputs	Intel® UHD Graphics 630 Multi output support : HDMI/DVI-D/D-Sub - HDMI 1.4b max. 4096x2160@24Hz / 2560x1600@60Hz - DVI-D with max. 1920x1200@60Hz - D-sub with max. 1920x1200@60Hz
Audio	8-Channel High Definition Audio
Boot Drive	240GB Solid State Boot Drive (SSD)
Video Storage	2 x 3.5" SATA A/V HDD (up to 20TB)
Operating System	Windows 10 Enterprise
Pre-Loaded VMS	Avigilon, Axis, Exacq, Genetec, Milestone

### Protocols

Networking	IPv4, UDP, TCP, IGMP, ARP, DHCP, DNS, HTTP, HTTPS, BONJOUR, NTP
Management	HTTP, HTTPS, Bonjour, ION API, SNMP
Security	Basic / Digest Authentication, SSL

### Software Features

Web Interface	Web GUI for remote config. / maintenance
Programming API	Bonjour discovery protocol ION API for configuration
Firmware Update	Fault-tolerant, remote accessible

### Mechanical / Environmental

Dimensions	12.20" (W) x 3.94" (H) x 10.43" (D)
Power Supply	Internal Standard TFX 12V, 200W (US Power Cord Included)
Security	Padlock Loop / Kensington Slot
Operating Temp.	0°C - 40°C
Warranty	3 Years Standard
Compliance	RoHS, CE and FCC Class B



[www.ionodes.com](http://www.ionodes.com)

**Head Office**  
1855 Bernard-Lefebvre,  
Laval, Quebec  
H7C 0A5, Canada

[sales@ionodes.com](mailto:sales@ionodes.com)

1.450.696.1060  
1.844.696.1060 (Toll Free)

**EMEA Office**  
15, Rue de l'Industrie,  
Bertrange, L-8069  
Luxembourg

[sales\\_eu@ionodes.com](mailto:sales_eu@ionodes.com)

+33 (0) 6 03 13 79 75

### Ordering Information

CR67-04-04TB	CR67 with 1 x 4TB of internal storage.
CR67-08-08TB	CR67 with 1 x 8TB of internal storage.
CR67-10-10TB	CR67 with 1 x 10TB of internal storage.
CR67-04-08TB	CR67 with 2 x 4TB of internal storage.
CR67-08-16TB	CR67 with 2 x 8TB of internal storage.
CR67-10-20TB	CR67 with 2 x 10TB of internal storage.
CR67-PWR-EUUK	CR67 power cord kit for EU and UK regions.