


Universal Dual-Monitor Mount Adapter

MODEL NUMBER: DMA1327SD

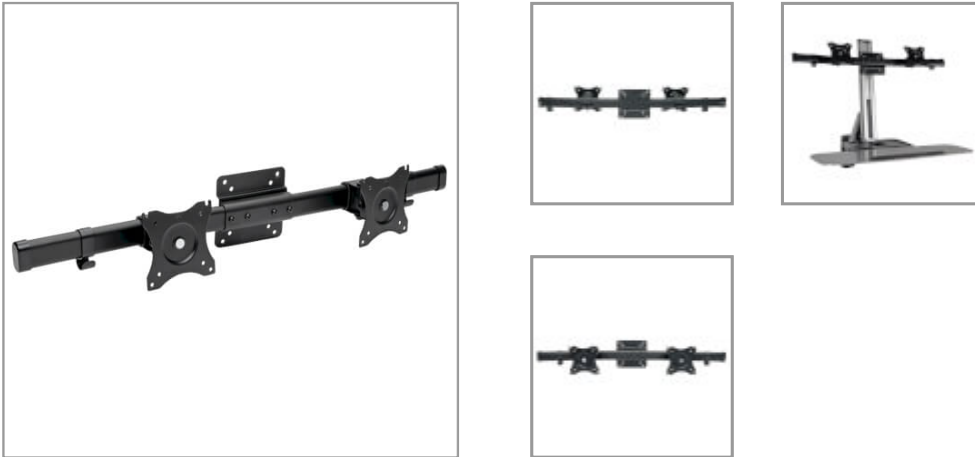

Dual-monitor kit converts a single-monitor display mount so it will hold 2 flat-screen 13-27 in. monitors at the same time.

Features

Mount 2 Flat-Screen Monitors on One Display Mount

This dual-monitor mount securely attaches to your current display mount, allowing you to use two monitors simultaneously without taking up any additional desk or table space in your workstation. Ideal for home, school or office use, the VESA-compliant adapter fits most flat-panel monitors, televisions and other displays from 13 to 27 inches.

Easy to Adjust to Your Liking With a Single Touch

Just one touch is all it takes to adjust the monitors' viewing angles and heights to fit your comfort level. The monitors tilt from -15° to $+15^{\circ}$ to give you flexibility in minimizing glare and providing comfortable viewing from multiple angles. They also rotate 360 degrees for viewing in portrait or landscape orientation.

Each VESA Mount Supports Up to 22 lb.

This dual-monitor kit mounts to your current display mount's 75 x 75 mm, 75 x 100, 100 x 75 mm or 100 x 100 mm VESA plate. Made from durable steel, the adapter features a scratch-resistant black powder-coated finish that blends with your décor and stands up to frequent handling. Mounting hardware is included. Keep in mind that the total mount weight must not exceed the maximum weight of the single display mount.

5-Year Warranty and Environmentally Responsible Design

The DMA1327SD comes with a 5-year warranty. It's manufactured in compliance with strict RoHS specifications, reflecting Tripp Lite's commitment to environmental responsibility.

Highlights

- Mounts to current single-display mount to leave valuable desk or table space clear
- Each mount supports up to 22 lb. and flat-screen displays from 13 to 27 in.
- Scratch-resistant powder-coated finish blends into your workspace décor
- Monitors tilt from -15° to $+15^{\circ}$ and rotate 360° to customize the ideal viewing angle
- Total weight must not exceed the max weight of the single monitor display mount

Applications

- Use 2 displays side-by-side for easier multitasking, editing multiple documents and watching video across screens

Package Includes

- (2) VESA head brackets
- Mounting plate
- (2) VESA bracket bars
- Bracket bar coupler
- (2) End caps
- (2) Cable hooks
- (2) End cap screws
- (4) M6 x 30 screws
- (8) M4 x 12 screws
- (12) M5 x 12 screws
- (12) D5 washers
- (4) M5 nuts
- Hex key, 4 mm
- Hex key, 6 mm



- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332212764
PHYSICAL	
Color	Black
Degrees of Motion	-15/+15 Tilt; 360 Rotate
Material of Construction	Steel
Maximum Screen Size (cm)	68.58
Maximum Screen Size (in.)	27
Maximum Weight Capacity (kg)	10
Maximum Weight Capacity (lbs.)	22
Minimum Screen Size (cm)	33.02
Minimum Screen Size (in.)	13
Motion	Full
Mounting Location	Desktop; Desk Clamp
Number of Displays	2
Unit Dimensions (hwd / cm)	31.7 x 4.7 x 5.3
Unit Dimensions (hwd / in.)	18.11 x 31.69 x 10
Unit Weight (kg)	2.45
Unit Weight (lbs.)	5.4
VESA Pattern (mm)	100x100; 100x75; 75x100; 75x75
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
Cord Management	Yes
CERTIFICATIONS	
Approvals	RoHS3, REACH and CE
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Product Warranty Period (U.S. & Canada)	5-year limited warranty
---	-------------------------

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>