


MLOC-4-LS2XMNM-3M

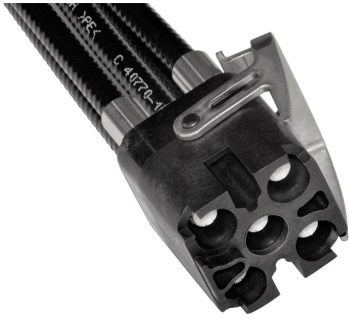

LSF2 SureFlex® Jumper with MLOC Male Multiport latching connector with interface type NEX10 Male and N Male four port, 3 m

- WARNING: DO NOT MATE WITH 4.1-9.5 DIN

Product Classification

Product Type	Wireless transmission cable assembly
Product Series	LSF2-50

General Specifications

Interface, Connector A	Nex10 Male
Interface, Connector B	N Male
Specification Sheet Revision Level	A

Dimensions

Length	3 m 9.843 ft
Nominal Size	3/8 in

Electrical Specifications

3rd Order IMD Dynamic	-119 dBm
3rd Order IMD Dynamic Test Method	Two +43 dBm carriers per IEC 62037

VSWR/Return Loss

Frequency Band	VSWR	Return Loss (dB)
1000–3000 MHz	1.08	29
3000–4200 MHz	1.08	29
4200–5000 MHz	1.09	28

Environmental Specifications

Immersion Test Method	Meets IEC 60529:2001, IP68 in mated condition
Weatherproofing Method	EPDM rubber boot

MLOC-4-LS2XMNM-3M

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

