


**Data sheet | Item number: 281-511**

Fuse plug; with pull-tab; for miniature metric fuses 5 x 20 mm and 5 x 25 mm;  
without blown fuse indication; 6 mm wide; gray



[www.wago.com/281-511](http://www.wago.com/281-511)

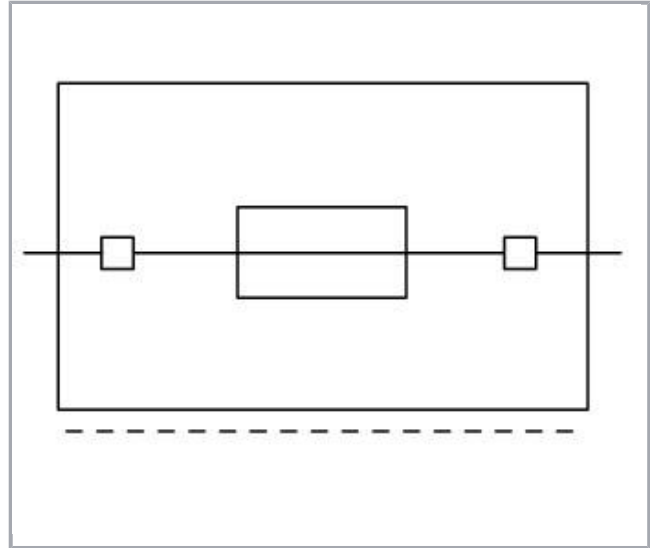

Subject to changes. Please also observe the further product documentation!

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.



Subject to changes. Please also observe the further product documentation!

RoHS   
Compliant

BOMcheck.net

Color:

## Item description

### Safety information 1:

Electrical ratings are given by the fuse.

## Data

### Electrical data

#### Ratings per IEC/EN 60664-1

Nominal voltage (III/3)	250 V
Rated current	6.3 A

### Geometrical Data

Width	6 mm / 0.236 inch
-------	-------------------

### Mechanical data

Marking level	Center marking
---------------	----------------

### Material Data

Color	gray
Insulation material	Polyamide 66 (PA 66)
Weight	6.1 g

### Commercial data

Product Group	1 (Rail Mounted Terminal Blocks)
Packaging type	BOX
Country of origin	CN
GTIN	4050821032540
Customs tariff number	85366990990




## Approvals / Certificates

Subject to changes. Please also observe the further product documentation!



WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.


## Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CSA DEKRA Certification B.V.	C22.2 No. 158	1505034
	KEMA/KEUR DEKRA Certification B.V.	EN 60947	NTR NL- 7135
	KEMA/KEUR DEKRA Certification B.V.	EN 60947	2160584.31

## Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	ABS American Bureau of Shipping	-	20- HG1941090- PDA
	ABS American Bureau of Shipping	EN 60947	20- HG1941090- PDA

## UL-Approvals

Logo	Approval	Additional Approval Text	Certificate name
	UL Underwriters Laboratories Inc.	UL 1059	20170731- E45172

## Counterpart




 
## Compatible products

Subject to changes. Please also observe the further product documentation!


 





WAGO Kontakttechnik GmbH & Co. KG  
 Hansastr. 27  
 32423 Minden  
 Phone: +49571 887-0 | Fax: +49571 887-169  
 Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
 We are always happy to take your call at +49 (571) 887-44222.




## General accessories

	<b>Item no.: 281-503</b> Shorting link; 5 x 20 mm; if the fuse plug is used as disconnect plug	<a href="http://www.wago.com/281-503">www.wago.com/281-503</a>
	<b>Item no.: 281-610</b> 3-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm <sup>2</sup> ; CAGE CLAMP®; 4,00 mm <sup>2</sup> ; gray	<a href="http://www.wago.com/281-610">www.wago.com/281-610</a>
	<b>Item no.: 281-656</b> 4-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm <sup>2</sup> ; CAGE CLAMP®; 4,00 mm <sup>2</sup> ; gray	<a href="http://www.wago.com/281-656">www.wago.com/281-656</a>
	<b>Item no.: 281-916</b> 2-conductor carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm <sup>2</sup> ; CAGE CLAMP®; 4,00 mm <sup>2</sup> ; gray	<a href="http://www.wago.com/281-916">www.wago.com/281-916</a>














## clamps

	<b>Item no.: 280-510</b> Triple-deck terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; green-yellow/blue/gray	<a href="http://www.wago.com/280-510">www.wago.com/280-510</a>
	<b>Item no.: 280-514</b> Double-deck terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; gray /gray	<a href="http://www.wago.com/280-514">www.wago.com/280-514</a>
	<b>Item no.: 280-528</b> Double-deck terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; gray /gray	<a href="http://www.wago.com/280-528">www.wago.com/280-528</a>
	<b>Item no.: 280-531</b> Double-deck terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; blue /gray	<a href="http://www.wago.com/280-531">www.wago.com/280-531</a>
	<b>Item no.: 280-532</b> Double-deck terminal block; with additional jumper position on lower level; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; blue/gray	<a href="http://www.wago.com/280-532">www.wago.com/280-532</a>
	<b>Item no.: 280-889</b> Triple-deck terminal block; with additional jumper position on lower level; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; gray/gray/gray	<a href="http://www.wago.com/280-889">www.wago.com/280-889</a>
	<b>Item no.: 280-891</b> Double-deck terminal block; with additional jumper position on lower level; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm <sup>2</sup> ; CAGE CLAMP®; 2,50 mm <sup>2</sup> ; gray/gray	<a href="http://www.wago.com/280-891">www.wago.com/280-891</a>

## Marking accessories

	<b>Item no.: 2009-114</b> WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; white	<a href="http://www.wago.com/2009-114">www.wago.com/2009-114</a>
	<b>Item no.: 2009-114/000-002</b> WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; yellow	<a href="http://www.wago.com/2009-114/000-002">www.wago.com/2009-114/000-002</a>
	<b>Item no.: 2009-114/000-005</b> WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; red	<a href="http://www.wago.com/2009-114/000-005">www.wago.com/2009-114/000-005</a>

Subject to changes. Please also observe the further product documentation!

	<p><b>Item no.: 2009-114/000-006</b>                      WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; blue</p>	<a href="http://www.wago.com/2009-114/000-006">www.wago.com/2009-114/000-006</a>
	<p><b>Item no.: 2009-114/000-007</b>                      WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; gray</p>	<a href="http://www.wago.com/2009-114/000-007">www.wago.com/2009-114/000-007</a>
	<p><b>Item no.: 2009-114/000-012</b>                      WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; orange</p>	<a href="http://www.wago.com/2009-114/000-012">www.wago.com/2009-114/000-012</a>
	<p><b>Item no.: 2009-114/000-023</b>                      WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; green</p>	<a href="http://www.wago.com/2009-114/000-023">www.wago.com/2009-114/000-023</a>
	<p><b>Item no.: 2009-114/000-024</b>                      WMB-Inline; for Smart Printer; 2000 pieces on roll; stretchable 4 - 4.2 mm; plain; snap-on type; violet</p>	<a href="http://www.wago.com/2009-114/000-024">www.wago.com/2009-114/000-024</a>
	<p><b>Item no.: 209-701</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; white</p>	<a href="http://www.wago.com/209-701">www.wago.com/209-701</a>
	<p><b>Item no.: 209-701/000-002</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; yellow</p>	<a href="http://www.wago.com/209-701/000-002">www.wago.com/209-701/000-002</a>
	<p><b>Item no.: 209-701/000-005</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; red</p>	<a href="http://www.wago.com/209-701/000-005">www.wago.com/209-701/000-005</a>
	<p><b>Item no.: 209-701/000-006</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; blue</p>	<a href="http://www.wago.com/209-701/000-006">www.wago.com/209-701/000-006</a>
	<p><b>Item no.: 209-701/000-007</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; gray</p>	<a href="http://www.wago.com/209-701/000-007">www.wago.com/209-701/000-007</a>
	<p><b>Item no.: 209-701/000-012</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; orange</p>	<a href="http://www.wago.com/209-701/000-012">www.wago.com/209-701/000-012</a>
	<p><b>Item no.: 209-701/000-017</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; light green</p>	<a href="http://www.wago.com/209-701/000-017">www.wago.com/209-701/000-017</a>
	<p><b>Item no.: 209-701/000-023</b>                      WSB marking card; as card; not stretchable; plain; snap-on type; green</p>	<a href="http://www.wago.com/209-701/000-023">www.wago.com/209-701/000-023</a>

Subject to changes. Please also observe the further product documentation!



**Item no.: 209-701/000-024**  
WSB marking card; as card; not stretchable; plain; snap-on type; violet

[www.wago.com/209-701/000-024](http://www.wago.com/209-701/000-024)



**Item no.: 793-4501**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; white

[www.wago.com/793-4501](http://www.wago.com/793-4501)



**Item no.: 793-4501/000-002**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; yellow

[www.wago.com/793-4501/000-002](http://www.wago.com/793-4501/000-002)



**Item no.: 793-4501/000-005**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; red

[www.wago.com/793-4501/000-005](http://www.wago.com/793-4501/000-005)



**Item no.: 793-4501/000-006**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; blue

[www.wago.com/793-4501/000-006](http://www.wago.com/793-4501/000-006)



**Item no.: 793-4501/000-007**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; gray

[www.wago.com/793-4501/000-007](http://www.wago.com/793-4501/000-007)



**Item no.: 793-4501/000-012**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; orange

[www.wago.com/793-4501/000-012](http://www.wago.com/793-4501/000-012)



**Item no.: 793-4501/000-014**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; brown

[www.wago.com/793-4501/000-014](http://www.wago.com/793-4501/000-014)



**Item no.: 793-4501/000-023**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; light green

[www.wago.com/793-4501/000-023](http://www.wago.com/793-4501/000-023)



**Item no.: 793-4501/000-024**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type; violet

[www.wago.com/793-4501/000-024](http://www.wago.com/793-4501/000-024)

## Downloads

### Documentation

#### Bid Text

281-511 GAEB X81 - Datei	Feb 19, 2019	xml 2.9 kB	Download
281-511 doc - Datei	Mar 14, 2017	doc 23.6 kB	Download

Subject to changes. Please also observe the further product documentation!

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.

## CAD/CAE-Data

### CAD data

2D/3D Models 281-511

[URL](#)

[Download](#)


### CAE data

WSCAD Universe 281-511

[URL](#)

[Download](#)

## Installation Notes

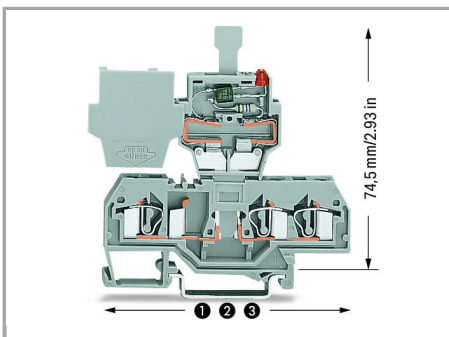

### Length of carrier terminal blocks with a fuse plug:

59 mm / 2.32 inch for 281-916

73.5 mm / 2.89 inch for 281-610

86 mm / 3.39 inch for 281-656

## Testing



Subject to changes. Please also observe the further product documentation!





Using fuse plugs with rail-mount terminal blocks for control circuit protection is highly advantageous because the function and wiring levels are separated:


- No additional cost for assembly and wiring
- 
- No risk of accidental contact with live parts when disconnecting the fuse plug
- 
- The fuse plug is completely separated from the carrier terminal block when replacing a fuse – away from current carrying parts
- 
- The fuse plug can be removed by service personnel
- 
- No unintentional reclosing of the circuit by another person
- 
- Quickly exchange a fuse by using a prepared "stand-by plug"
- 

Fuse plug features for quick and safe applications:

- Optional LED indicates blown fuse
- 
- 

Subject to changes. Please also observe the further product documentation!

- Top-of-unit marking slot provides clear carrier terminal block identification
- 
- Two test slots with touch contacts
- 
- Terminal blocks/plugs provide high-density wiring in a width of just 6 mm
- 
- May be used as a disconnect plug in combination with a shorting link
- 

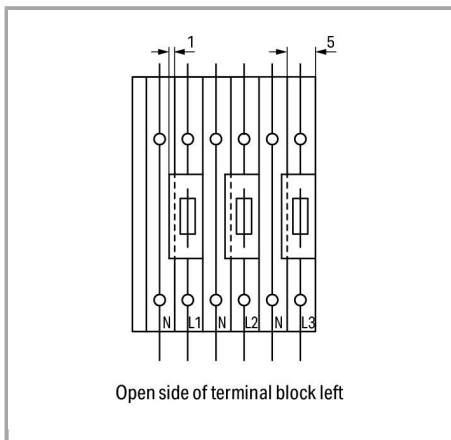

When a corresponding neutral circuit is adjacent to the fuse plug, a 5 mm wide space-saving terminal block may be used, as a 6 mm fuse plug may overlap the terminal block (see diagram).

For 5 mm wide carrier terminal blocks can be used with end plates, for example.

Subject to changes. Please also observe the further product documentation!