

## Datasheet

### DOOR AUTOMATION/ DWSR-102U, Universal arm

#### Product description

The long awaited Digiway Spring Return offers high quality and high performance, assisted by a chain driven spring mechanism it is ideally suited for heavy manual environments and offers fully automatic door automation when required.

With a satin anodised aluminium finish, the Digiway Spring Return adapts to all environments and offers high aesthetics.

Suitable for people with reduced mobility, the Digiway Spring Return is the answer for door automation in high traffic sites such as front doors or commercial sites.



#### Key features

- Heavy duty door operator
- 60 minutes fire rated - EN1634-1
- Semi-automatic (spring return) & Fully automatic (motor return)
- Built in programmer & receiver
- Universal arm included
- Compatible with CDVI transmitters



Certification



DEEE


**RoHS**

Certification




-10°C to 55°C

All the information contained within this document (pictures, drawing, features, dimensions, specifications), could be perceptibly different and can be changed without prior notice. - April 2020 - CDVI\_DWSR-102U\_DS\_02\_EN\_A4\_C

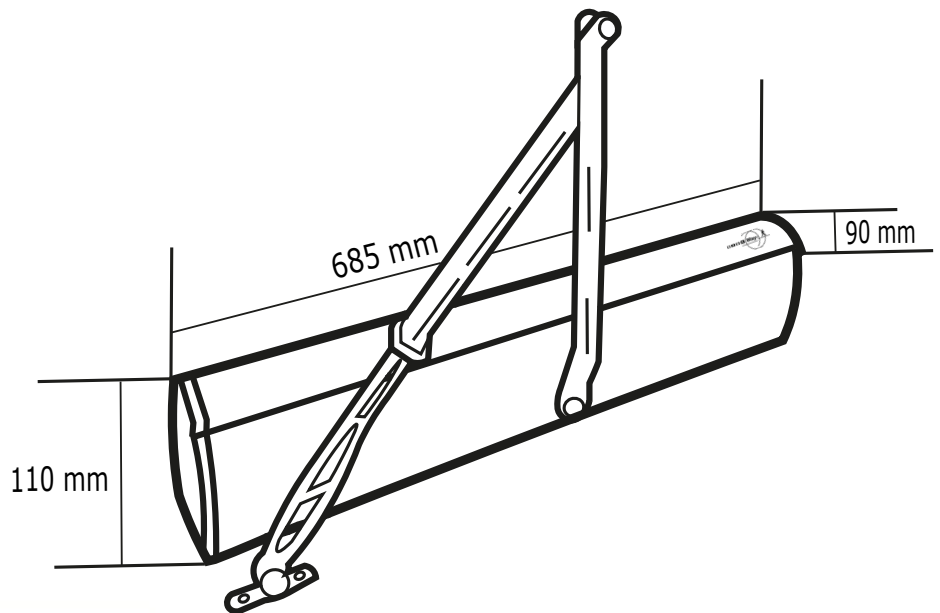

## Usage

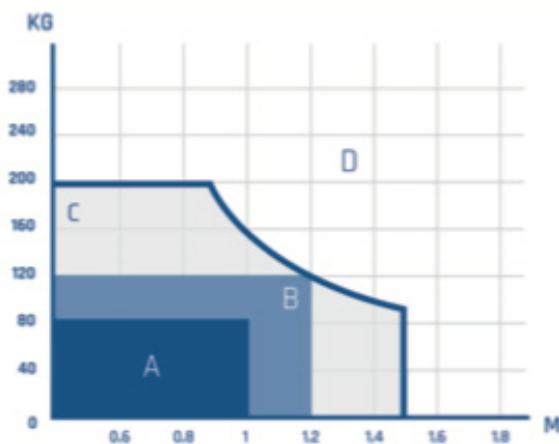

- Zone A:** Very intensive use (600 cycles/day)
- Zone B:** Intensive use (200-300 cycles/day)
- Zone C:** Use with reduced speed
- Zone D:** Do not use

## Product Information

**Material:** Satin anodised aluminium (SAA)

**Transmitter Memory:** 50

**Transmitter Encoding:** Keeloq® Hopping Code

## Electrical Specifications

**Power supply:** 230Vac, 50Hz

**Power for auxiliary devices:** 12Vdc / 500mA (max)

**Power for electrolock:** 12Vdc / 1A (max) or 24Vdc / 0.5A (max)

**Max current:** 100W