


LED-FE025i2-220

220" Indoor LED 2.53mm Full HD Bundle

Datasheet

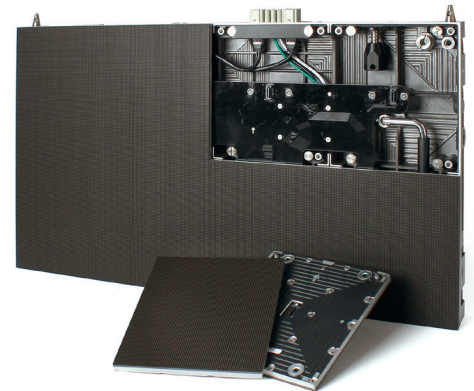

Nothing less than magnificent

For premium large surface visualization, NEC's fine pitch LED FE Series bundles provide standard resolution, direct view LED screens for applications in meeting spaces and exclusive signage. With a depth of just 3.2in., plus complete internal cabling, the FE series presents a sleek profile for a bezel-free viewing experience. With excellent viewing angles, consistent vibrant colors and superb brightness; the FE Series delivers content that gets noticed. This Full HD bundle is designed for viewing from 8ft to an optimal 15ft and includes everything required to install an LED wall, including a power bar, framing, mounting and controller. Designed with high quality components and maintenance access from the front, the FE Series provides a display solution with longevity and good return on investment. The FE Series bundles are the prime solution for boardrooms, auditoriums, luxury retail environments and control rooms.

Benefits

16:9 Aspect Ratio – enabling standard Full HD content to be utilized, saving time and cost in content creation.

Quality product – designed and tested in Germany, LED fine pitch product of the highest quality.


Ultimate Versatility – small 16:9 modules allowing excellent flexibility within the available space.

Excellent Homogeneity – uniform color and brightness across the entire wall.

Outstanding Picture Quality – through the use of Kinglight LEDs.

Direct View LED Kit		LED-FE025i2-220
DISPLAY	Panel Technology	Direct View LED
	Pixel Configuration	3-1 SMD (Black)
	Panel Resolution	1920 x 1080
	Aspect Ratio	16:9
	Pixel Pitch	2.53mm
	Brightness (Max)	1000 cd/m ²
	Contrast Ratio (typical)	5000:1
	Viewing Angle (typical)	80/80 horizontal / 70/70 vertical
	Dimming Capability	256 levels
	Color Processing	Up to 16 bit
	Displayable Colors	281 Trillion
	Refresh Rate	Up to 3840 Hz
CONNECTIVITY	Input Terminals Digital	1 x 3G SDI; 1 x DVI-D; 1 x HDMI
	External Control	1 x GenLock; 1 x LAN
POWER CONSUMPTION	On (typical)	3008 Watts
	Max	7680 Watts
PHYSICAL SPECIFICATIONS	Dimensions (W x H x D)	193.1 x 112.4 x 3.2in / 4904 x 2856 x 81mm
	Weight (Net)	1053.8lbs / 478kg
ENVIRONMENTAL CONDITIONS	Operating Temperature	-4° to 104°F / -20° to 40°C
	Operating Humidity	10% to 80%
	Storage Temperature	-4° to 113°F / -20° to 45°C
	Storage Humidity	10% to 85%
	IP Rating	IP20
SHIPS WITH	LED Controller, LED Modules (64 Cabinets, 256 Pixel Cards), Overframe Kit (8x8), Pixel Card Removal Tool, Power Bar; Spare Parts Kit, Wall mount (8x8), Control PC, Monitor, Keyboard, Mouse	
LIMITED WARRANTY	2 years	

Every bundle ships with

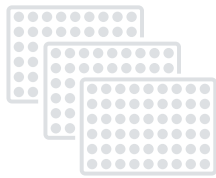

LED Modules



Power Bar



Control PC




Pixel Card Removal Tool



Overframe



Spare Parts

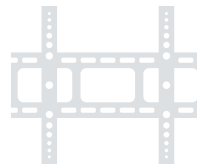

Wallmount



LED Controller

All rights reserved in favor of their respective owners. All hardware and software names are brand names and/or registered trademarks of the respective manufacturers. All specifications are subject to change without notice.