


2N® INDOOR TALK

ELEGANT ANSWERING UNIT WITH HD SOUND

The design of the 2N® Indoor Talk answering unit will suit every flat or home. The aesthetic appearance of this product was achieved by using a glass surface and striking backlighting of its icons. However, we placed particular emphasis on selecting the highest-quality audio components in order to achieve a high-quality sound. This means you can talk to visitors outside as if they were standing right next to you. Invite them in and press the icon to open the door from the comfort of your home.

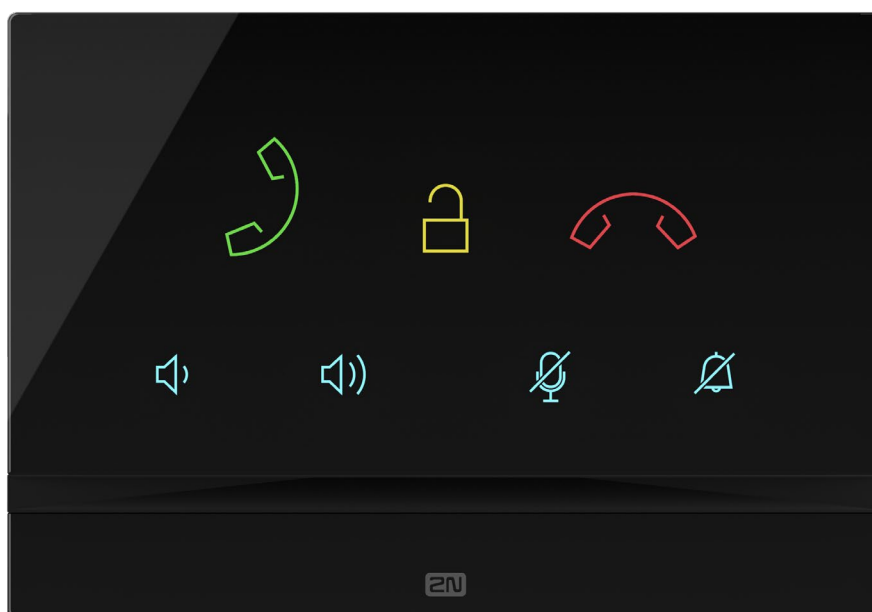


- **Luxury design and materials**
- **Modification to your requirements**
- **HD quality sound with high volume**
- **Precision installation box**
- **Concierge call**
- **Simple upgrade to a video communicator**

VARIANTS



BLACK
91378401

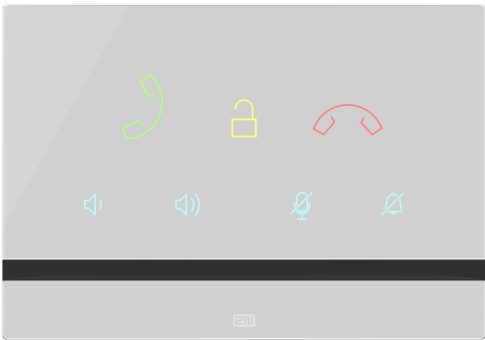

WHITE
91378401WH

TECHNICAL PARAMETERS

Power supply

Type	12 V / 1 A DC or PoE
PoE	802.3af
Reverse polarity protection	Yes

User interface

Controls	7 capacitive buttons with RGB LED backlighting
Operation	Press and hold the RESET button to restore factory settings, 3 LED status indicators

Audio

Microphone	Integrated
Speaker	Integrated, 2W
Induction loop output	600 mV RMS
Codecs	G.711, G.722, G.729, L16/16kHz

Interface

LAN	10/100BaseT, RJ-45
Recommended cabling	Cat5e or higher

Doorbell Input

Input type	Switching contact (button/relay)
Contact type	Normally open (NO)
Contact parameters	Up to 50V/5mA, DC

Mechanical properties

Operating temperature	0 to 50°C
Storage temperature	-20 to 70°C
Relative operating humidity	10 to 90 % (non-condensing)
Recommended altitude	0 to 2000 m
Dimensions (W x H x D)	185 x 128 x 48.2 mm
Weight	387g