


SKINDICHT® SVFK

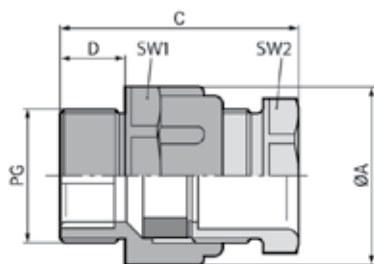

The SKINDICHT® SVFK is a compact strain relief connector for flat cable made of polystyrene. The special neoprene bushing provides a flexible seal over a wide range of cable widths. Ideal for use with ÖLFLEX® FLAT, ÖLFLEX® LIFT F, or ÖLFLEX® CRANE F.

■ Approvals



■ Technical data

■ Material:

- body: polystyrene
- seal: neoprene bushing

■ IP Protection:

IP54

■ RAL Color:

light gray (RAL 7035)

■ Temperature range:

-20°C to +60°C

Part number	Thread	Minimum flat cable width		Maximum flat cable width		Minimum cable thickness		Maximum cable thickness		Wrenching flats		Overall length (C) in	Thread length (D) in	Pack size
		in	mm	in	mm	in	mm	in	mm	(SW1) in	(SW2) in			
52005470	PG 16	—	—	0.591	15	—	—	0.197	5	1.064	0.906	1.56	0.39	25
52005680	PG 21	0.394	10	0.808	20.5	0.118	3	0.315	8	1.261	1.182	1.69	0.43	25
52005690	PG 29	0.591	15	1.064	27	0.158	4	0.453	11.5	1.655	1.615	1.77	0.43	25
52005700	PG 36	0.985	25	1.340	34	0.158	4	0.453	11.5	2.088	1.970	2.01	0.51	10
52005710	PG 42	1.182	30	1.576	40	0.197	5	0.473	12	2.364	2.167	2.13	0.51	5
52005720	PG 48	1.379	35	1.773	45	0.197	5	0.473	12	2.561	2.364	2.17	0.59	5