

COOPER LIGHTING - SURE-LITES®

DESCRIPTION

The All Pro Series Remote is the most economical LED Emergency Light Remote for general purpose applications. The durable, injection molded thermoplastic material resists discoloration due to UV radiation. The mounting plate employs a snap-fit construction to further improve the installation time. The All Pro Series Remote Heads are fully adjustable, insuring that light can be put where it is needed

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

Electrical

- 3.6V DC Input Voltage

Lampholder/Mounting Plate Construction

- Flame resistant and impact resistant, injection molded thermoplastic
 - Lamp heads adjust 80° from vertical with 358° rotation
 - Universal mounting plate

Code Compliance

- UL 924 Listed
 - Damp Location Listed (APR)
 - Wet Location Listed (APWR)

Warranty

- Five-year warranty


Head/Lamp Data

- Long Life LED Emergency Heads
 - Fully adjustable
 - High impact thermoplastic
 - Matches housing finish
 - 3.6V, .78W DC Long Lasting LED Heads



APR / APWR SERIES

REMOTE HEADS
 LED EMERGENCY HEADS
 WET AND
 DAMP LISTED HEADS

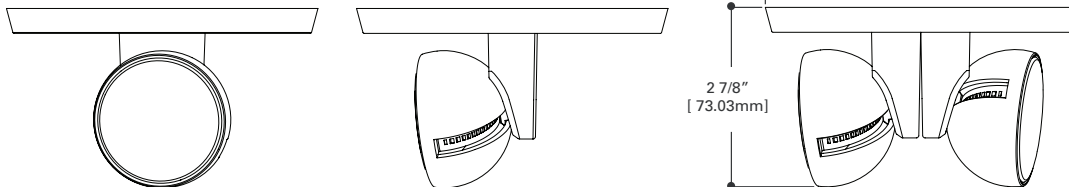

TOTALLY PREDICTABLE
RELIABILITY

ORDERING INFORMATION

Sample Number: APR1

Family

APR1=Single Head Remote, Damp Location Listed
 APR2=Double Head Remote, Damp Location Listed
 APWR1=Single Head Remote, Wet Location Listed
 APWR2=Double Head Remote, Wet Location Listed

ENERGY DATA

Power Consumption is equal to LED head wattage.