



511 nVent CADDY EZ Riser for Copper Tube – 5110500CP

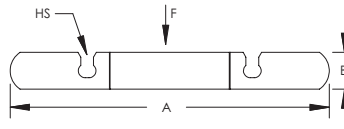

- Recommended for suspending vertical type K or L copper tubing risers
- Conforms with Federal Specification WW-H-171 (Type 8), Manufacturers Standardization Society (MSS) SP-58 (Type 8)
- Slotted holes make assembly easy, eliminating loose hardware
- Bolts are accessible from the front, serrated washer head design means no wrench required on back side for tightening

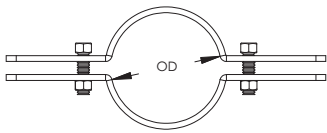

Part Number	5110500CP
Material	Steel
Finish	Copper Electroplated
Pipe Size	5"
Outer Diameter (OD)	5 1/8"
Hole Size (HS)	9/16"
Length (L)	2"
A	14 5/8"
B	1 1/2"
Screw Diameter (Sc)	1/2"
Screw Length (L)	2"
Static Load (F)	500 lb
Standard Packaging Quantity	10 pc
UPC	78285636972

Clamp is fitted for copper tube and should be installed below a coupling or shear lug, with bolts torqued to recommended value.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

