


nVent CADDY Speed Link SLK with Hook – SLK2L5R2



- Complete system includes wire, locking device and pre-assembled hook end fitting
- Hooks to a wide range of nVent CADDY fasteners
- Fastens to the building structure or hanging services by looping around and hooking to wire rope
- Easy to remove for applications requiring maintenance
- Spring latch helps provide secure connection
- Insert cable through hole and use bottom side of hook as an end stop
- Also available in Y-hook configuration

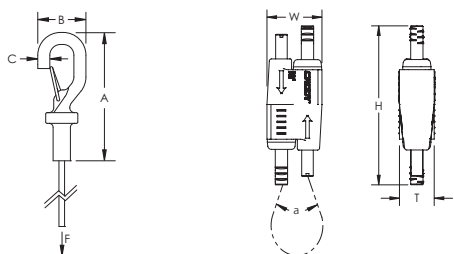

Part Number	SLK2L5R2
Material	Steel Polypropylene Zinc Alloy
Finish	Electrogalvanized
Static Load Safety Factor	5:1
Wire Rope Diameter	2 mm
Wire Rope Length	16.4'
A	2.24"
B	0.87"
C	0.22"
Height (H)	2.15"
Width (W)	3/4"
Thickness (T)	1/2"
Angle (a)	90° Max
Static Load (F)	100 lb
Certifications	cULus SMACNA SPEED LINK SLK

Part Number	SLK2L5R2
Standard Packaging Quantity	15 x 2 pc
UPC	78285685107
EAN-13	8711893144048

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

