



H-PSM Conduit to Flange Clip, Side Mount – 16P24SM

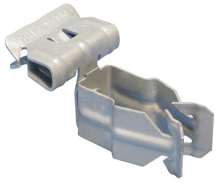

- Requires only a hammer to install
- Available for EMT, rigid and aluminum conduit
- Will pivot thru 360°

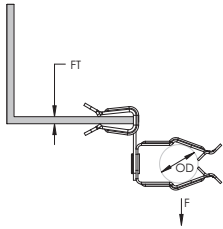

Part Number	16P24SM
Orientation	Side Mount
Material	Spring Steel
Finish	nVent CADDY Armour
EMT Conduit Size	1"
Outer Diameter (OD)	1.181" – 1.378"
Flange Thickness (FT)	1/8" – 1/4"
Ultimate Static Load (F)	25 lb
Standard Packaging Quantity	100 pc
UPC	78285611266
EAN-13	8711893752649

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

