


# Snap Close Conduit/Pipe Clamp – 32M



- May be used for either vertical or horizontal installations
- Eliminates need for offset bending conduit
- Finger closure, no tools required

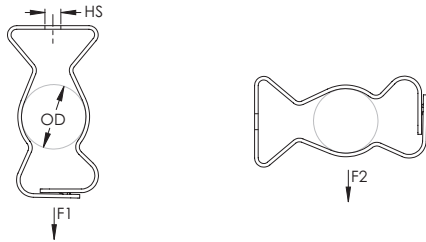

Part Number	32M
Material	Spring Steel
Finish	nVent CADDY Armour
EMT Conduit Size	2"
Rigid Conduit/Pipe Size	2"
Outer Diameter (OD)	1.969" – 2.362"
Hole Size (HS)	9/32"
Hole Type	Plain
Static Load 1 (F1)	100 lb
Static Load 2 (F2)	25 lb
Certifications	cULus
Standard Packaging Quantity	100 pc
UPC	78285670232
EAN-13	8711893701333

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

