


# 418 J-Hanger – 4180250EG



- Recommended for the suspension of stationary non-insulated pipe lines
- T-slot hole for bolt head permits disengagement of side bolt without removing the nut (sizes 1/2" thru 4" only)
- Side hole permits wall mounting (sizes 1/2" thru 4" only)
- Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 5)

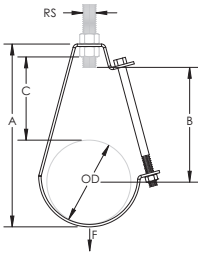

Part Number	4180250EG
Material	Steel
Finish	Electrogalvanized
Pipe Size	2 1/2"
Rod Size (RS)	1/2"
A	6 1/4"
B	3 13/16"
C	2 13/16"
Static Load (F)	800 lb
Standard Packaging Quantity	25 pc
UPC	78285633999

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2020 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

